

MASTER Value GLASS LED candles and lustres

MASTER VLE LEDCandleD3.4-40W E14 B35 927CLG

MASTER Value Glass LED lustres feature a classic heritage design, these filament LED lamps combine the familiar shapes of incandescent candles and lustres with the benefits of long-lasting LED technology. These glass LED lustres offer more energy savings than normal LED candles and lustres. At the same time, they also provide customers with a good light experience, enhanced by excellent dimming performance (dimmable LED candles). MASTER Value Glass LED lustres deliver significant energy savings, using 30% less energy compared to normal glass LED candles and provide excellent quality of light. By offering a lifetime of 15,000 hours, these dimmable LED candles and lustres also reduce maintenance costs.

Product data

General information	
Lighting Technology	LED
Flux measurement reference	Sphere
Switching Cycle	20,000
Nominal lifetime	15,000 h
Cap base	E14 [E14]

Light technical	
Colour Code	927 [CCT of 2700K]
Luminous Flux	470 lm
Colour designation	Warm White (WW)
Correlated Colour Temperature	2700 K

Luminous Efficacy (rated) (Nom)	138.00 lm/W
Colour consistency	<6
Colour rendering index (CRI)	90
LLMF at end of nominal lifetime (nom.)	70 %
Flickering value (PstLM)	1
Stroboscopic effect	0.4

Operating and electrical	
Line Frequency	50 to 60 Hz
Input frequency	50 to 60 Hz
Power Consumption	3.4 W
Lamp current (nom.)	20 mA

MASTER Value GLASS LED candles and lustres

Wattage equivalent	40 W
Starting time (nom.)	0.5 s
Warm-up time to 60% light	0.5 s
Power Factor (Fraction)	0.7
Voltage (nom.)	220-240 V

Temperature

T-Case maximum (nom.)	80 °C
-----------------------	-------

Controls and dimming

Dimmable	Only with specific dimmers
----------	----------------------------

Mechanical and housing

Lamp Finish	Clear
Bulb shape	B35 [B 35 mm]

Approval and application


Energy Efficiency Class	D
-------------------------	---

Energy consumption kWh/1,000 hours	4 kWh
EPREL registration number	574369
CE mark	Yes
EU RoHS compliant	Yes

Product data


Full EOC	871951435543900
Order product name	MAS VLE LEDCandleD3.4-40W E14 B35 927CLG
Order code	35543900
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929003059502
Full product name	MASTER VLE LEDCandleD3.4-40W E14 B35 927CLG
EAN/UPC - Case	8719514355446

Dimensional drawing

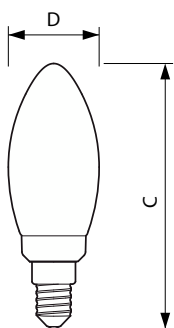


Product	D	C
MAS VLE LEDCandleD3.4-40W E14 B35 927CLG	35 mm	97 mm

Photometric data

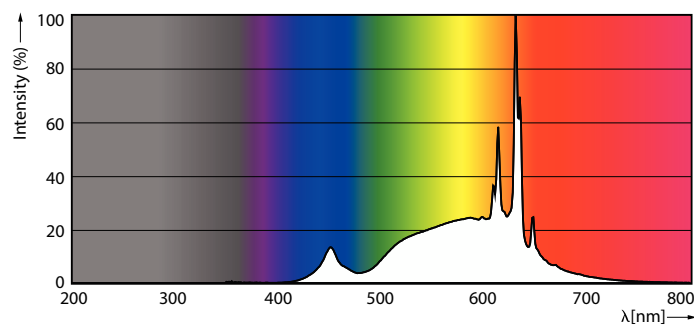


Spectral Power Distribution Colour - MAS VLE LEDCandleD3.4-40W E14 B35 927CLG

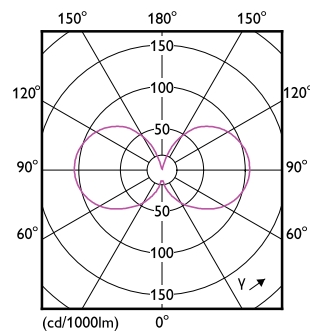

Light Distribution Diagram - MAS VLE LEDCandleD3.4-40W E14 B35 927CLG

MASTER Value GLASS LED candles and lustres


Photometric data

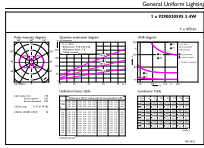


General uniform lighting - MAS VLE LEDCandleD3.4-40W E14 B35 927CLG

General uniform lighting - MAS VLE LEDCandleD3.4-40W E14 B35 927CLG

Lifetime

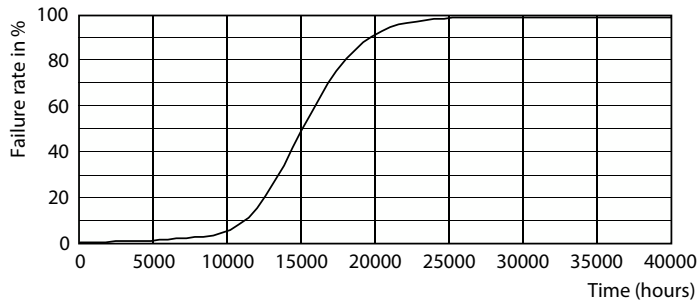

Life Expectancy Diagram - MAS VLE LEDCandleD3.4-40W E14 B35 927CLG

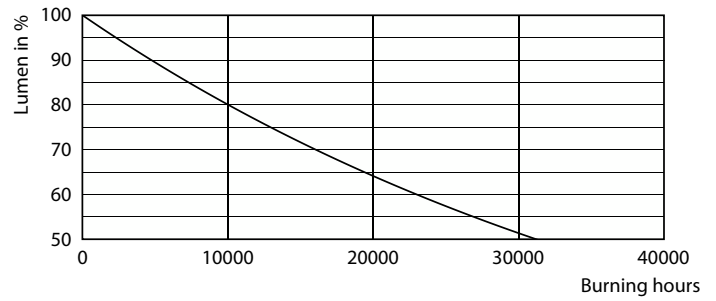

Lumen Maintenance Diagram - MAS VLE LEDCandleD3.4-40W E14 B35 927CLG

