



# CorePro GLASS LED candles and lustres

## CorePro LEDCandleND2-25W ST35 E14 827CLG

Featuring a classic heritage design, these filament LED candles combine the familiar shapes of classic incandescent bulbs with the benefits of long-lasting LED technology. The LED candle bulb is a very easy choice for people who are looking for a retrofit LED replacement, it provides 90% energy savings compared with conventional lamps. CorePro Glass LED bulbs provide excellent quality of light for stairway lighting. The LED candle bulb offers a lifetime of 15,000 hours to reduce maintenance costs.

### Product data

General information		Stroboscopic effect	
Lighting Technology	LED		0.4
Flux measurement reference	Sphere	Operating and electrical	
Switching Cycle	20,000	Line Frequency	50 to 60 Hz
Nominal lifetime	15,000 h	Input frequency	50 to 60 Hz
Cap base	E14 [E14]	Power Consumption	2 W
Light technical		Lamp current (nom.)	20 mA
Colour Code	827 [CCT of 2700K]	Wattage equivalent	25 W
Luminous Flux	250 lm	Starting time (nom.)	0.5 s
Colour designation	Warm White (WW)	Warm-up time to 60% light	0.5 s
Correlated Colour Temperature	2700 K	Power Factor (Fraction)	0.4
Luminous Efficacy (rated) (Nom)	125.00 lm/W	Voltage (nom.)	220-240 V
Colour consistency	<6	Temperature	
Colour rendering index (CRI)	80	T-Case maximum (nom.)	36 °C
LLMF at end of nominal lifetime (nom.)	70 %		
Flickering value (PstLM)	1		

# CorePro GLASS LED candles and lustres

Controls and dimming	
Dimmable	No

Mechanical and housing	
Lamp Finish	Clear
Bulb shape	ST35

Approval and application	
Energy Efficiency Class	E
Energy-saving product	Yes
Suitable for accent lighting	No
Energy consumption kWh/1,000 hours	2 kWh
EPREL registration number	387362
CE mark	Yes

EU RoHS compliant	Yes
-------------------	-----


Product data	
Full EOC	871951434772400
Order product name	CorePro LEDCandleND2-25W ST35 E14 827CLG
Order code	34772400
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929001238592
Full product name	CorePro LEDCandleND2-25W ST35 E14 827CLG
EAN/UPC - Case	8719514347731

## Dimensional drawing




Product	D	C
CorePro LEDCandleND2-25W ST35 E14 827CLG	35 mm	97 mm

## Photometric data

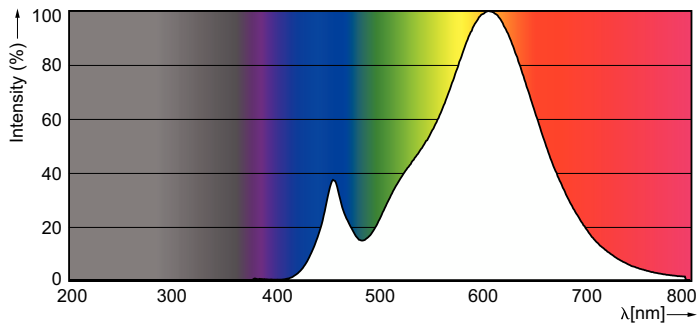


Spectral Power Distribution Colour - CorePro LEDCandleND2-25W ST35 E14 827CLG

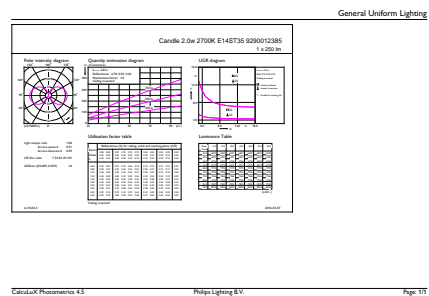

General uniform lighting - CorePro LEDCandleND2-25W ST35 E14 827CLG

# CorePro GLASS LED candles and lustres

## Photometric data

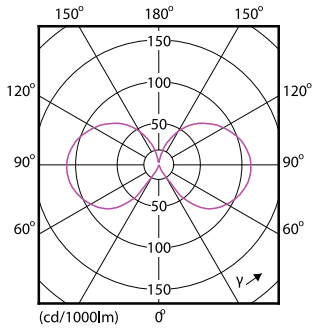


Light Distribution Diagram - CorePro LEDCandleND2-25W ST35 E14 827CLG

## Lifetime



Life Expectancy Diagram - CorePro LEDCandleND2-25W ST35 E14 827CLG

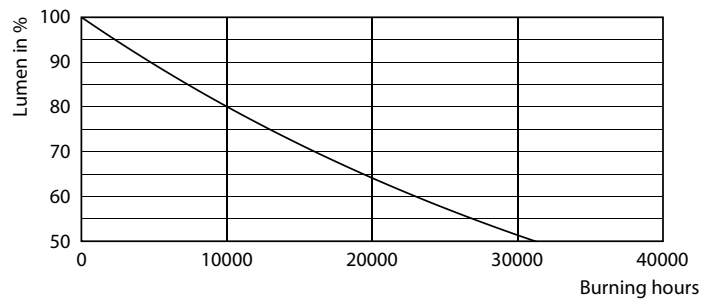

Lumen Maintenance Diagram - CorePro LEDCandleND2-25W ST35 E14 827CLG

