



CorePro GLASS LED candles and lustres

CorePro LEDCandleND 2-25W B35 B22 827CLG

Featuring a classic heritage design, these filament LED candles combine the familiar shapes of classic incandescent bulbs with the benefits of long-lasting LED technology. The LED candle bulb is a very easy choice for people who are looking for a retrofit LED replacement, it provides 90% energy savings compared with conventional lamps. CorePro Glass LED bulbs provide excellent quality of light for stairway lighting. The LED candle bulb offers a lifetime of 15,000 hours to reduce maintenance costs.

Product data

General information		Stroboscopic effect	0.4
Lighting Technology	LED	Operating and electrical	
Flux measurement reference	Sphere	Line Frequency	50 to 60 Hz
Switching Cycle	20,000	Input frequency	50 to 60 Hz
Nominal lifetime	15,000 h	Power Consumption	2 W
Cap base	B22 [B22]	Lamp current (nom.)	20 mA
Light technical		Wattage equivalent	25 W
Colour Code	827 [CCT of 2700K]	Starting time (nom.)	0.5 s
Luminous Flux	250 lm	Warm-up time to 60% light	0.5 s
Colour designation	Warm White (WW)	Power Factor (Fraction)	0.41
Correlated Colour Temperature	2700 K	Voltage (nom.)	220-240 V
Luminous Efficacy (rated) (Nom)	125.00 lm/W	Temperature	
Colour consistency	<6	T-Case maximum (nom.)	36 °C
Colour rendering index (CRI)	80		
LLMF at end of nominal lifetime (nom.)	70 %		
Flickering value (PstLM)	1		

CorePro GLASS LED candles and lustres

Controls and dimming

Dimmable	No
----------	----

Mechanical and housing

Lamp Finish	Clear
Bulb shape	B35 [B 35 mm]


Approval and application

Energy Efficiency Class	E
Energy consumption kWh/1,000 hours	2 kWh
EPREL registration number	400292
EU RoHS compliant	Yes

Product data



Full EOC	871951434724300
Order product name	CorePro LEDCandleND 2-25W B35 B22 827CLG
Order code	34724300
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929001815692
Full product name	CorePro LEDCandleND 2-25W B35 B22 827CLG
EAN/UPC – Case	8719514347250

Dimensional drawing

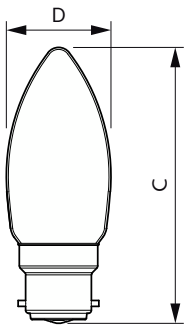

Product	D	C
CorePro LEDCandleND 2-25W B35 B22 827CLG	35 mm	93 mm

Photometric data

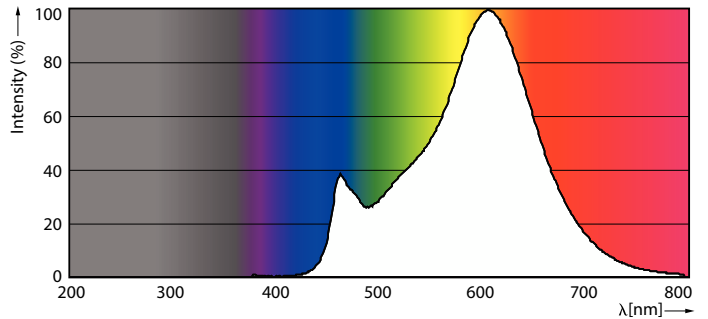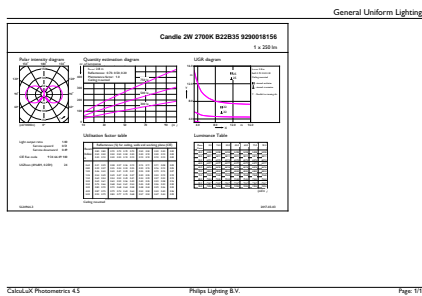


General uniform lighting - CorePro LEDCandleND 2-25W B35 B22 827CLG

Spectral Power Distribution Colour - CorePro LEDCandleND 2-25W B35 B22 827CLG


CorePro GLASS LED candles and lustres

Photometric data

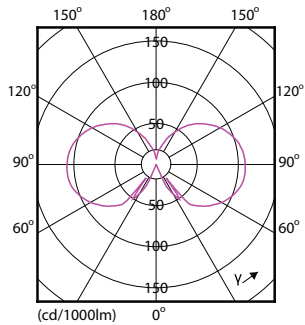


Light Distribution Diagram - CorePro LEDCandleND 2-25W B35 B22 827CLG

Lifetime

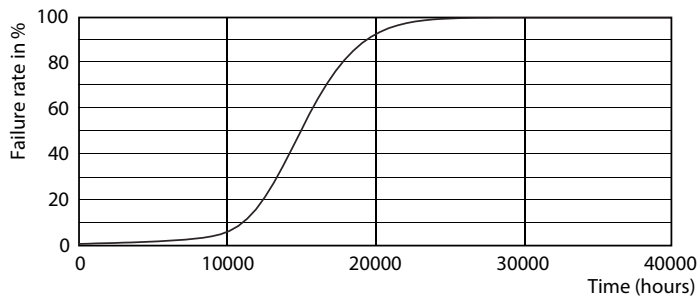

Life Expectancy Diagram - CorePro LEDCandleND 2-25W B35 B22 827CLG

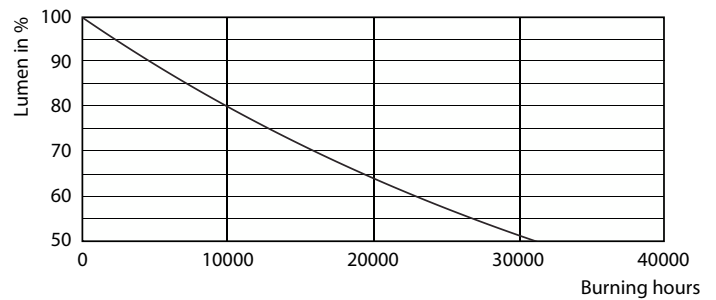

Lumen Maintenance Diagram - CorePro LEDCandleND 2-25W B35 B22 827CLG

