



# CorePro GLASS LED candles and lustres

## CorePro LEDCandle ND6.5-60W B35E14827CLG

Featuring a classic heritage design, these filament LED candles combine the familiar shapes of classic incandescent bulbs with the benefits of long-lasting LED technology. The LED candle bulb is a very easy choice for people who are looking for a retrofit LED replacement, it provides 90% energy savings compared with conventional lamps. CorePro Glass LED bulbs provide excellent quality of light for stairway lighting. The LED candle bulb offers a lifetime of 15,000 hours to reduce maintenance costs.

### Product data

General information		Stroboscopic effect	
Lighting Technology	LED		0.9
Flux measurement reference	Sphere	Operating and electrical	
Switching Cycle	20,000	Line Frequency	50 to 60 Hz
Nominal lifetime	15,000 h	Input frequency	50 to 60 Hz
Cap base	E14 [E14]	Power Consumption	6.5 W
Light technical		Lamp current (nom.)	50 mA
Colour Code	827 [CCT of 2700K]	Wattage equivalent	60 W
Luminous Flux	806 lm	Starting time (nom.)	0.5 s
Colour designation	Warm White (WW)	Warm-up time to 60% light	0.5 s
Correlated Colour Temperature	2700 K	Power Factor (Fraction)	0.55
Luminous Efficacy (rated) (Nom)	124.00 lm/W	Voltage (nom.)	220-240 V
Colour consistency	<6	Temperature	
Colour rendering index (CRI)	80	T-Case maximum (nom.)	55 °C
LLMF at end of nominal lifetime (nom.)	70 %		
Flickering value (PstLM)	1		

# CorePro GLASS LED candles and lustres

## Controls and dimming

Dimmable	No
----------	----

## Mechanical and housing

Lamp Finish	Clear
Bulb shape	B35 [B 35 mm]


## Approval and application

Energy Efficiency Class	E
Energy consumption kWh/1,000 hours	7 kWh
EPREL registration number	387441
CE mark	Yes
EU RoHS compliant	Yes

## Product data



Full EOC	871951434746500
Order product name	CorePro LEDCandle ND6.5-60W B35E14827CLG
Order code	34746500
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929002028092
Full product name	CorePro LEDCandle ND6.5-60W B35E14827CLG
EAN/UPC – Case	8719514347472

## Dimensional drawing

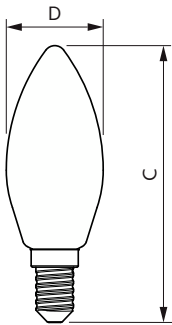

Product	D	C
CorePro LEDCandle ND6.5-60W B35E14827CLG	35 mm	97 mm

## Photometric data

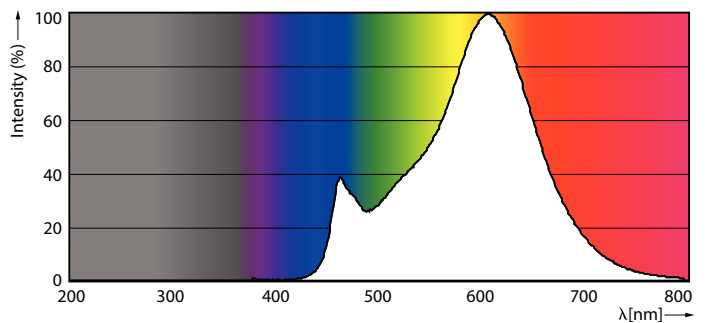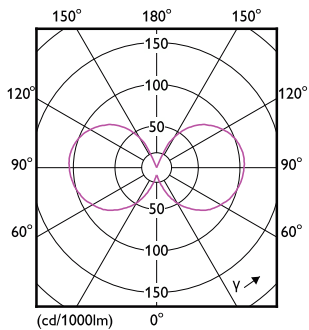


Light Distribution Diagram - CorePro LEDCandle ND6.5-60W B35E14827CLG

Spectral Power Distribution Colour - CorePro LEDCandle ND6.5-60W B35E14827CLG

# CorePro GLASS LED candles and lustres


## Photometric data

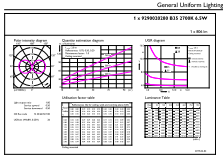


General uniform lighting - CorePro LEDCandle ND6.5-60W B35E14827CLG

General uniform lighting - CorePro LEDCandle ND6.5-60W B35E14827CLG

## Lifetime

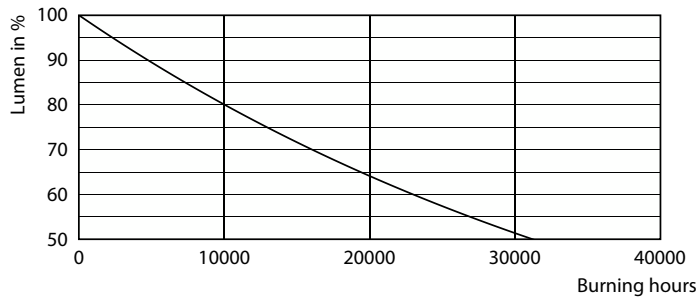

Lumen Maintenance Diagram - CorePro LEDCandle ND6.5-60W B35E14827CLG

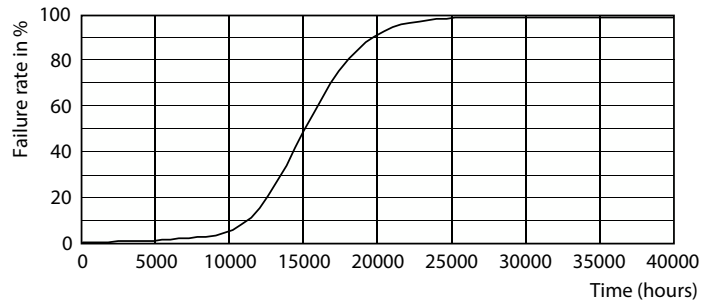

Life Expectancy Diagram - CorePro LEDCandle ND6.5-60W B35E14827CLG

