



CorePro GLASS LED candles and lustres

CorePro LEDCandle ND 2.2-25W B35 E14 FRG

Featuring a classic heritage design, these filament LED candles combine the familiar shapes of classic incandescent bulbs with the benefits of long-lasting LED technology. The LED candle bulb is a very easy choice for people who are looking for a retrofit LED replacement, it provides 90% energy savings compared with conventional lamps. CorePro Glass LED bulbs provide excellent quality of light for stairway lighting. The LED candle bulb offers a lifetime of 15,000 hours to reduce maintenance costs.

Product data

General information	
Lighting Technology	LED
Flux measurement reference	Sphere
Switching Cycle	20,000
Nominal lifetime	15,000 h
Cap base	E14 [E14]

Light technical	
Colour Code	827 [CCT of 2700K]
Luminous Flux	250 lm
Colour designation	Warm White (WW)
Correlated Colour Temperature	2700 K
Luminous Efficacy (rated) (Nom)	113.00 lm/W
Colour consistency	<6
Colour rendering index (CRI)	80
LLMF at end of nominal lifetime (nom.)	70 %
Flickering value (PstLM)	1

Stroboscopic effect	0.4
---------------------	-----

Operating and electrical	
Line Frequency	50 to 60 Hz
Input frequency	50 to 60 Hz
Power Consumption	2.2 W
Lamp current (nom.)	21 mA
Wattage equivalent	25 W
Starting time (nom.)	0.5 s
Warm-up time to 60% light	0.5 s
Power Factor (Fraction)	0.4
Voltage (nom.)	220-240 V

Temperature	
T-Case maximum (nom.)	36 °C

CorePro GLASS LED candles and lustres

Controls and dimming

Dimmable	No
----------	----

Mechanical and housing

Lamp Finish	Frosted
Bulb shape	B35 [B 35 mm]


Approval and application

Energy Efficiency Class	E
Energy consumption kWh/1,000 hours	3 kWh
EPREL registration number	387381
CE mark	Yes
EU RoHS compliant	Yes

Product data


Full EOC	871951434679600
Order product name	CorePro LEDCandle ND 2.2-25W B35 E14 FRG
Order code	34679600
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929001345292
Full product name	CorePro LEDCandle ND 2.2-25W B35 E14 FRG
EAN/UPC – Case	8719514346802

Dimensional drawing

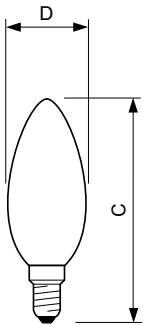


Product	D	C
CorePro LEDCandle ND 2.2-25W B35 E14 FRG	35 mm	97 mm

 Photometric data




Spectral Power Distribution Colour - CorePro LEDCandle ND 2.2-25W B35 E14 FRG

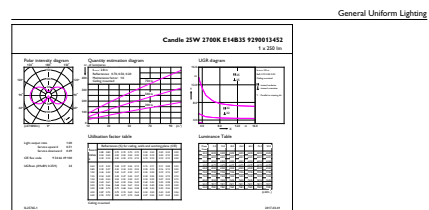

General uniform lighting - CorePro LEDCandle ND 2.2-25W B35 E14 FRG


CorePro GLASS LED candles and lustres

Photometric data

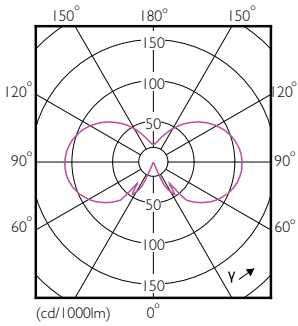


Light Distribution Diagram - CorePro LEDCandle ND 2.2-25W B35 E14 FRG

Lifetime

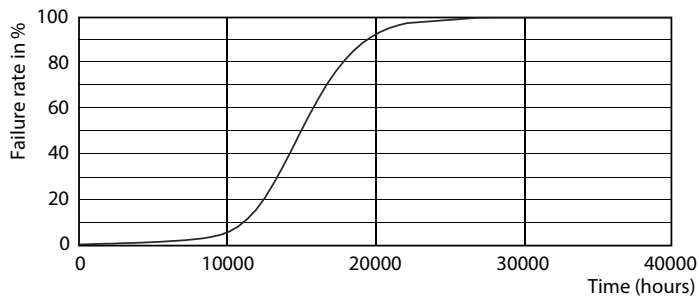

Life Expectancy Diagram - CorePro LEDCandle ND 2.2-25W B35 E14 FRG

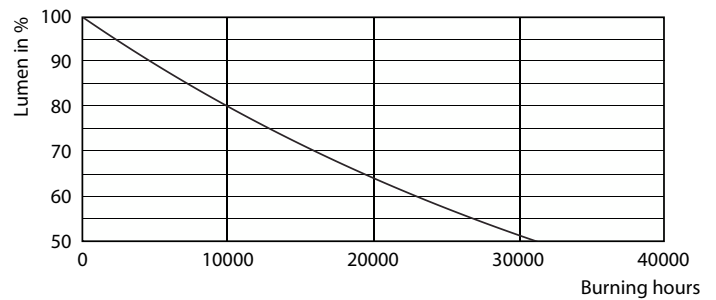

Lumen Maintenance Diagram - CorePro LEDCandle ND 2.2-25W B35 E14 FRG

