



# CorePro GLASS LED candles and lustres

## CorePro LEDCandleND 2.2-25W BA35 E14 FRG

Featuring a classic heritage design, these filament LED candles combine the familiar shapes of classic incandescent bulbs with the benefits of long-lasting LED technology. The LED candle bulb is a very easy choice for people who are looking for a retrofit LED replacement, it provides 90% energy savings compared with conventional lamps. CorePro Glass LED bulbs provide excellent quality of light for stairway lighting. The LED candle bulb offers a lifetime of 15,000 hours to reduce maintenance costs.

### Product data

General information		Stroboscopic effect	
Lighting Technology	LED	Stroboscopic effect	0.4
Flux measurement reference	Sphere	Operating and electrical	
Switching Cycle	20,000	Line Frequency	50 to 60 Hz
Nominal lifetime	15,000 h	Input frequency	50 to 60 Hz
Cap base	E14 [E14]	Power Consumption	2.2 W
Light technical		Lamp current (nom.)	21 mA
Colour Code	827 [CCT of 2700K]	Wattage equivalent	25 W
Luminous Flux	250 lm	Starting time (nom.)	0.5 s
Colour designation	Warm White (WW)	Warm-up time to 60% light	0.5 s
Correlated Colour Temperature	2700 K	Power Factor (Fraction)	0.4
Luminous Efficacy (rated) (Nom)	113.00 lm/W	Voltage (nom.)	220-240 V
Colour consistency	<6	Temperature	
Colour rendering index (CRI)	80	T-Case maximum (nom.)	36 °C
LLMF at end of nominal lifetime (nom.)	70 %		
Flickering value (PstLM)	1		

# CorePro GLASS LED candles and lustres

## Controls and dimming

Dimmable	No
----------	----

## Mechanical and housing

Lamp Finish	Frosted
Bulb shape	BA35

## Approval and application

Energy Efficiency Class	E
Energy consumption kWh/1,000 hours	3 kWh
EPREL registration number	387387
CE mark	Yes
EU RoHS compliant	Yes

## Product data

 
Full EOC	871951434685700
Order product name	CorePro LEDCandleND 2.2-25W BA35 E14 FRG
Order code	34685700
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929001345892
Full product name	CorePro LEDCandleND 2.2-25W BA35 E14 FRG
EAN/UPC – Case	8719514346864

## Dimensional drawing




Product	D	C
CorePro LEDCandleND 2.2-25W BA35 E14 FRG	35 mm	123 mm

## Photometric data




Spectral Power Distribution Colour - CorePro LEDCandleND 2.2-25W BA35 E14 FRG

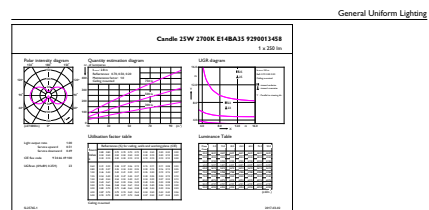

General Uniform Lighting - CorePro LEDCandleND 2.2-25W BA35 E14 FRG


# CorePro GLASS LED candles and lustres

## Photometric data

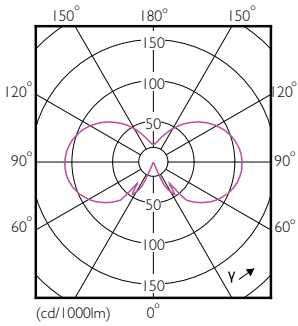


Light Distribution Diagram - CorePro LEDCandleND 2.2-25W BA35 E14 FRG

## Lifetime

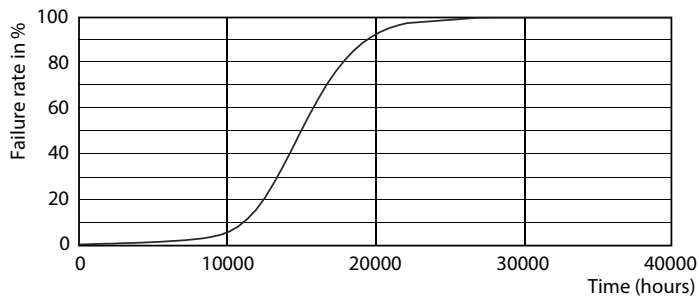

Life Expectancy Diagram - CorePro LEDCandleND 2.2-25W BA35 E14 FRG

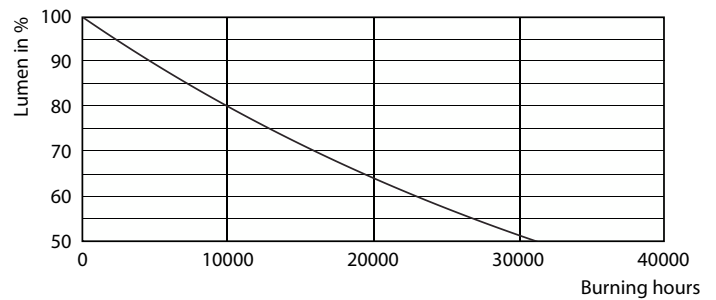

Lumen Maintenance Diagram - CorePro LEDCandleND 2.2-25W BA35 E14 FRG

