



CorePro GLASS LED candles and lustres

CorePro LEDCandleND4.3-40W E14 827B35FRG

Featuring a classic heritage design, these filament LED candles combine the familiar shapes of classic incandescent bulbs with the benefits of long-lasting LED technology. The LED candle bulb is a very easy choice for people who are looking for a retrofit LED replacement, it provides 90% energy savings compared with conventional lamps. CorePro Glass LED bulbs provide excellent quality of light for stairway lighting. The LED candle bulb offers a lifetime of 15,000 hours to reduce maintenance costs.

Product data

| General information | | Stroboscopic effect | |
|--|--------------------|---------------------------|-------------|
| Lighting Technology | LED | | 0.4 |
| Flux measurement reference | Sphere | Operating and electrical | |
| Switching Cycle | 20,000 | Line Frequency | 50 to 60 Hz |
| Nominal lifetime | 15,000 h | Input frequency | 50 to 60 Hz |
| Cap base | E14 [E14] | Power Consumption | 4.3 W |
| Light technical | | Lamp current (nom.) | 35 mA |
| Colour Code | 827 [CCT of 2700K] | Wattage equivalent | 40 W |
| Luminous Flux | 470 lm | Starting time (nom.) | 0.5 s |
| Colour designation | Warm White (WW) | Warm-up time to 60% light | 0.5 s |
| Correlated Colour Temperature | 2700 K | Power Factor (Fraction) | 0.5 |
| Luminous Efficacy (rated) (Nom) | 109.00 lm/W | Voltage (nom.) | 220-240 V |
| Colour consistency | <6 | Temperature | |
| Colour rendering index (CRI) | 80 | T-Case maximum (nom.) | 55 °C |
| LLMF at end of nominal lifetime (nom.) | 70 % | | |
| Flickering value (PstLM) | 1 | | |

CorePro GLASS LED candles and lustres

Controls and dimming

| | |
|----------|----|
| Dimmable | No |
|----------|----|

Mechanical and housing

| | |
|-------------|---------------|
| Lamp Finish | Frosted |
| Bulb shape | B35 [B 35 mm] |


Approval and application

| | |
|------------------------------------|--------|
| Energy Efficiency Class | F |
| Energy consumption kWh/1,000 hours | 5 kWh |
| EPREL registration number | 387382 |
| CE mark | Yes |
| EU RoHS compliant | Yes |

Product data


| | |
|-----------------------------------|--|
| Full EOC | 871951434718200 |
| Order product name | CorePro LEDCandleND4.3-40W E14 827B35FRG |
| Order code | 34718200 |
| SAP numerator – quantity per pack | 1 |
| Numerator – packs per outer box | 10 |
| Material number (12NC) | 929001345392 |
| Full product name | CorePro LEDCandleND4.3-40W E14 827B35FRG |
| EAN/UPC – Case | 8719514347199 |

Dimensional drawing

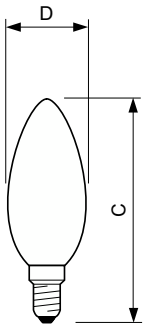


| Product | D | C |
|--|-------|-------|
| CorePro LEDCandleND4.3-40W E14 827B35FRG | 35 mm | 97 mm |

 Photometric data



Spectral Power Distribution Colour - CorePro LEDCandleND4.3-40W E14 827B35FRG

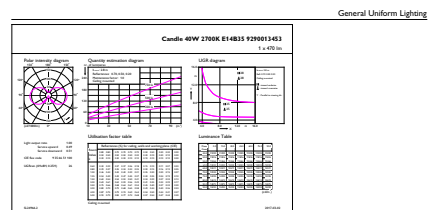

General Uniform Lighting - CorePro LEDCandleND4.3-40W E14 827B35FRG

CorePro GLASS LED candles and lustres

Photometric data




Light Distribution Diagram - CorePro LEDCandleND4.3-40W E14 827B35FRG

Lifetime



Life Expectancy Diagram - CorePro LEDCandleND4.3-40W E14 827B35FRG

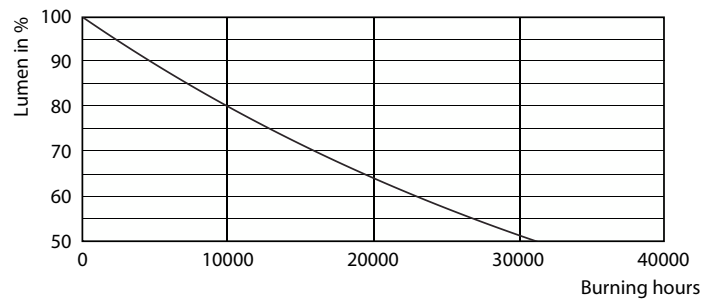

Lumen Maintenance Diagram - CorePro LEDCandleND4.3-40W E14 827B35FRG

