



CorePro GLASS LED candles and lustres

CorePro LEDCandleND4.3-40W B22 827B35CLG

Featuring a classic heritage design, these filament LED candles combine the familiar shapes of classic incandescent bulbs with the benefits of long-lasting LED technology. The LED candle bulb is a very easy choice for people who are looking for a retrofit LED replacement, it provides 90% energy savings compared with conventional lamps. CorePro Glass LED bulbs provide excellent quality of light for stairway lighting. The LED candle bulb offers a lifetime of 15,000 hours to reduce maintenance costs.

Product data

General information		Stroboscopic effect	
Lighting Technology	LED		0.4
Flux measurement reference	Sphere	Operating and electrical	
Switching Cycle	20,000	Line Frequency	50 to 60 Hz
Nominal lifetime	15,000 h	Input frequency	50 to 60 Hz
Cap base	B22 [B22]	Power Consumption	4.3 W
Light technical		Lamp current (nom.)	40 mA
Colour Code	827 [CCT of 2700K]	Wattage equivalent	40 W
Luminous Flux	470 lm	Starting time (nom.)	0.5 s
Colour designation	Warm White (WW)	Warm-up time to 60% light	0.5 s
Correlated Colour Temperature	2700 K	Power Factor (Fraction)	0.41
Luminous Efficacy (rated) (Nom)	109.00 lm/W	Voltage (nom.)	220-240 V
Colour consistency	<6	Temperature	
Colour rendering index (CRI)	80	T-Case maximum (nom.)	45 °C
LLMF at end of nominal lifetime (nom.)	70 %		
Flickering value (PstLM)	1		

CorePro GLASS LED candles and lustres

Controls and dimming

Dimmable	No
----------	----

Mechanical and housing

Lamp Finish	Clear
Bulb shape	B35 [B 35 mm]


Approval and application

Energy Efficiency Class	F
Energy consumption kWh/1,000 hours	5 kWh
EPREL registration number	387404
EU RoHS compliant	Yes

Product data


Full EOC	871951434728100
Order product name	CorePro LEDCandleND4.3-40W B22 827B35CLG
Order code	34728100
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929001889992
Full product name	CorePro LEDCandleND4.3-40W B22 827B35CLG
EAN/UPC – Case	8719514347298

Dimensional drawing

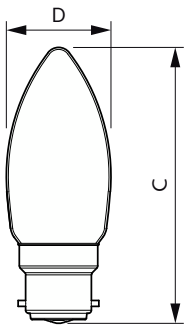


Product	D	C
CorePro LEDCandleND4.3-40W B22 827B35CLG	35 mm	93 mm

Photometric data

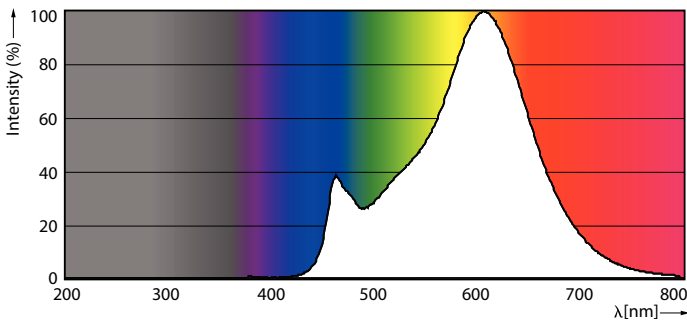


Spectral Power Distribution Colour - CorePro LEDCandleND4.3-40W B22 827B35CLG

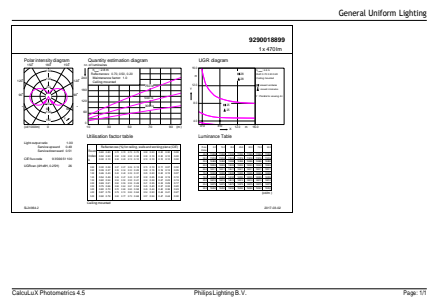

General uniform lighting - CorePro LEDCandleND4.3-40W B22 827B35CLG


CorePro GLASS LED candles and lustres

Photometric data

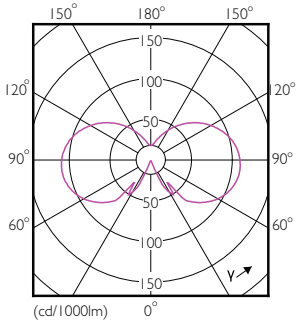


Light Distribution Diagram - CorePro LEDCandleND4.3-40W B22 827B35CLG

Lifetime

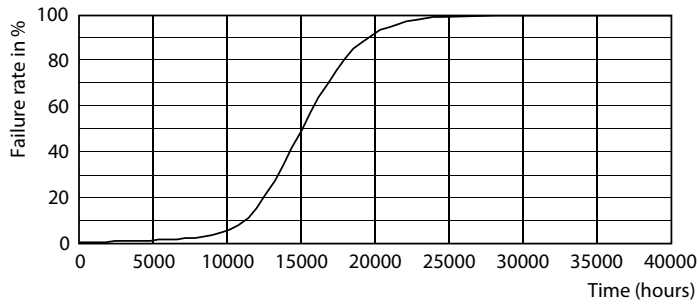

Life Expectancy Diagram - CorePro LEDCandleND4.3-40W B22 827B35CLG

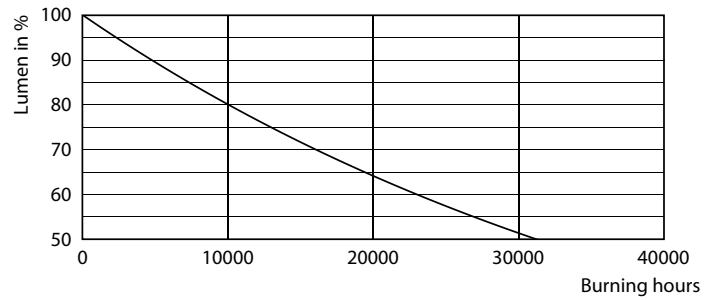

Lumen Maintenance Diagram - CorePro LEDCandleND4.3-40W B22 827B35CLG

