



MASTER Value Glass LED bulbs

MASTER VLE LEDBulbD 3.4-40W B22 A60 927FR G

Featuring a classic heritage design, these filament LED bulbs combine the familiar shapes of incandescent bulbs with the benefits of long-lasting LED technology. These MASTER Value Glass LED bulbs offer more energy savings than normal glass LED bulbs. At the same time, they also provide customers with good light experience, enhanced by excellent dimming performance (dimmable glass LED bulbs). MASTER Value Glass LED Bulbs deliver significant energy savings, using 30% less energy compared to normal LED bulbs and provide excellent quality of light. By offering a lifetime of 15,000 hours, these dimmable LED bulbs also reduce maintenance costs.

Product data


General information		Colour rendering index (CRI)	
Lighting Technology	LED	LLMF at end of nominal lifetime (nom.)	70 %
Flux measurement reference	Sphere	Flickering value (PstLM)	0.9
Switching Cycle	20,000	Stroboscopic effect	0.4
Nominal lifetime	15,000 h	Operating and electrical	
Cap base	B22 [B22]	Line Frequency	50 to 60 Hz
Light technical		Input frequency	50 to 60 Hz
Colour Code	927 [CCT of 2700K]	Power Consumption	3.4 W
Luminous Flux	470 lm	Lamp current (nom.)	24 mA
Colour designation	Warm White (WW)	Wattage equivalent	40 W
Correlated Colour Temperature	2700 K	Starting time (nom.)	0.5 s
Luminous Efficacy (rated) (Nom)	138.00 lm/W	Warm-up time to 60% light	0.5 s
Colour consistency	<6	Power Factor (Fraction)	0.6

MASTER Value Glass LED bulbs

Voltage (nom.)	220-240 V
Temperature	
T-Case maximum (nom.)	70 °C
Controls and dimming	
Dimmable	Only with specific dimmers
Mechanical and housing	
Lamp Finish	Frosted
Bulb shape	A60 [A 60 mm]
Approval and application	
Energy Efficiency Class	D
Energy consumption kWh/1,000 hours	4 kWh


EPREL registration number	453245
EU RoHS compliant	Yes
Product data	
Full EOC	871951432471800
Order product name	MAS VLE LEDBulbD 3.4-40W B22 A60 927FR G
Order code	32471800
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929003010202
Full product name	MASTER VLE LEDBulbD 3.4-40W B22 A60 927FR G
EAN/UPC – Case	8719514324725

Dimensional drawing

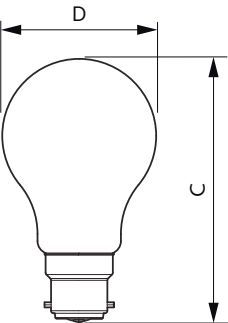


Product	D	C
MAS VLE LEDBulbD 3.4-40W B22 A60 927FR G	60 mm	103 mm

Photometric data

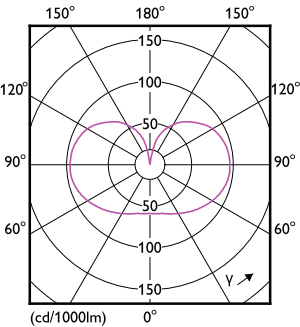


Light Distribution Diagram - MAS VLE LEDBulbD 3.4-40W B22 A60 927FR G

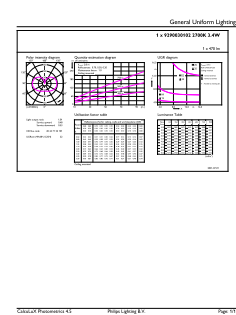

General uniform lighting - MAS VLE LEDBulbD 3.4-40W B22 A60 927FR G


MASTER Value Glass LED bulbs

Photometric data

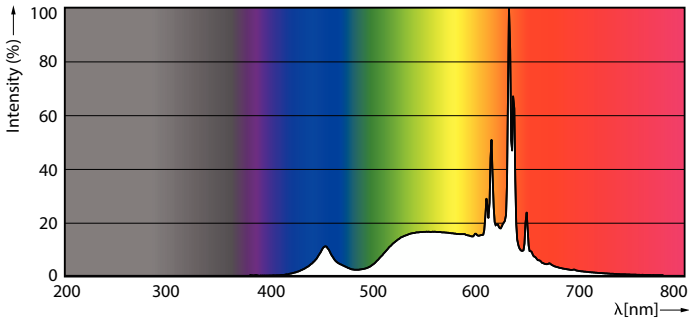


Spectral Power Distribution Colour - MAS VLE LEDBulbD 3.4-40W B22 A60 927FR G

Lifetime

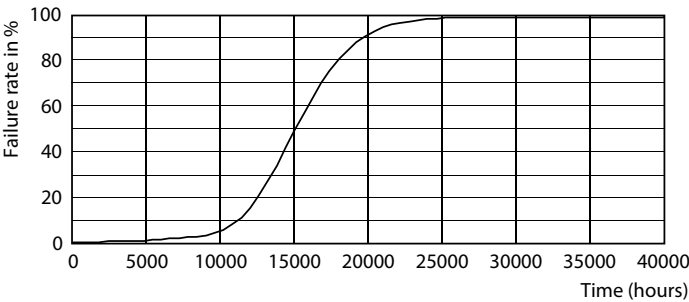

Life Expectancy Diagram - MAS VLE LEDBulbD 3.4-40W B22 A60 927FR G

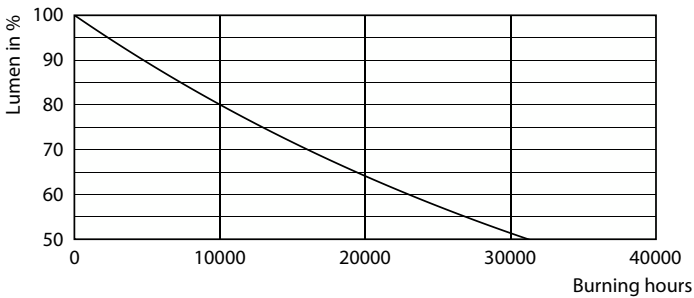

Lumen Maintenance Diagram - MAS VLE LEDBulbD 3.4-40W B22 A60 927FR G

