



# MASTER Value Glass LED bulbs

## MASTER VLE LEDBulbD7.2-75W B22 A60 927 FR G

Featuring a classic heritage design, these filament LED bulbs combine the familiar shapes of incandescent bulbs with the benefits of long-lasting LED technology. These MASTER Value Glass LED bulbs offer more energy savings than normal glass LED bulbs. At the same time, they also provide customers with good light experience, enhanced by excellent dimming performance (dimmable glass LED bulbs). MASTER Value Glass LED Bulbs deliver significant energy savings, using 30% less energy compared to normal LED bulbs and provide excellent quality of light. By offering a lifetime of 15,000 hours, these dimmable LED bulbs also reduce maintenance costs.

### Product data


General information		Colour rendering index (CRI)	
Lighting Technology	LED		90
Flux measurement reference	Sphere	LLMF at end of nominal lifetime (nom.)	70 %
Switching Cycle	20,000	Flickering value (PstLM)	0.9
Nominal lifetime	15,000 h	Stroboscopic effect	0.4
Cap base	B22 [B22]		
Light technical		Operating and electrical	
Colour Code	927 [CCT of 2700K]	Line Frequency	50 to 60 Hz
Luminous Flux	1,055 lm	Input frequency	50 to 60 Hz
Colour designation	Warm White (WW)	Power Consumption	7.2 W
Correlated Colour Temperature	2700 K	Lamp current (nom.)	49 mA
Luminous Efficacy (rated) (Nom)	146.00 lm/W	Wattage equivalent	75 W
Colour consistency	<6	Starting time (nom.)	0.5 s
		Warm-up time to 60% light	0.5 s
		Power Factor (Fraction)	0.6

# MASTER Value Glass LED bulbs

Voltage (nom.)	220-240 V
<b>Temperature</b>	
T-Case maximum (nom.)	70 °C
<b>Controls and dimming</b>	
Dimmable	Only with specific dimmers
<b>Mechanical and housing</b>	
Lamp Finish	Frosted
Bulb shape	A60 [A 60 mm]
<b>Approval and application</b>	
Energy Efficiency Class	D
Energy consumption kWh/1,000 hours	8 kWh


EPREL registration number	453257
EU RoHS compliant	Yes
<b>Product data</b>	
Full EOC	871951432495400
Order product name	MAS VLE LEDBulbD7.2-75W B22 A60 927 FR G
Order code	32495400
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929003011402
Full product name	MASTER VLE LEDBulbD7.2-75W B22 A60 927 FR G
EAN/UPC - Case	8719514324961

## Dimensional drawing

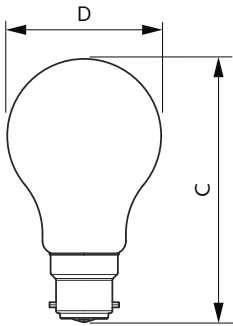


Product	D	C
MAS VLE LEDBulbD7.2-75W B22 A60 927 FR G	60 mm	103 mm

## Photometric data

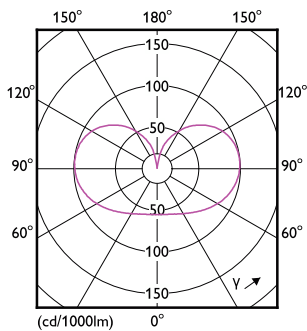


Light Distribution Diagram - MAS VLE LEDBulbD7.2-75W B22 A60 927 FR G

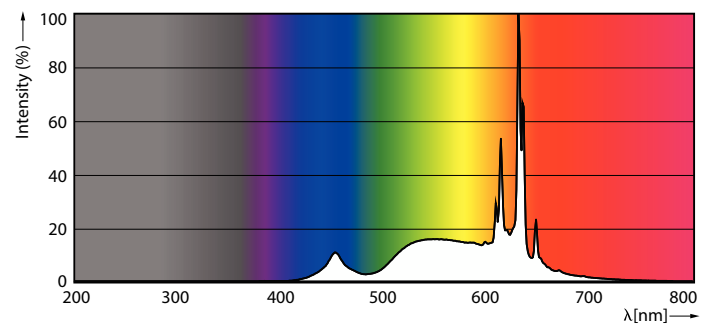

Spectral Power Distribution Colour - MAS VLE LEDBulbD7.2-75W B22 A60 927 FR G

# MASTER Value Glass LED bulbs

## Photometric data

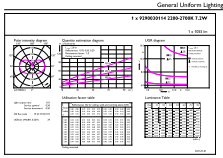


General uniform lighting - MAS VLE LEDBulbD7.2-75W B22 A60 927 FR G

## Lifetime



Life Expectancy Diagram - MAS VLE LEDBulbD7.2-75W B22 A60 927 FR G

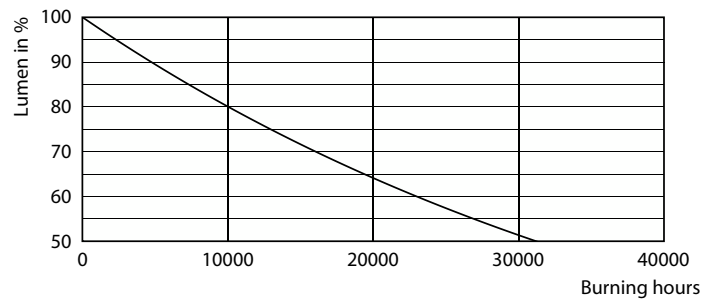

Lumen Maintenance Diagram - MAS VLE LEDBulbD7.2-75W B22 A60 927 FR G

