



CorePro GLASS LED candles and lustres

CorePro LEDCandleND 2-25W E14B35 827CL G

Featuring a classic heritage design, these filament LED candles combine the familiar shapes of classic incandescent bulbs with the benefits of long-lasting LED technology. The LED candle bulb is a very easy choice for people who are looking for a retrofit LED replacement, it provides 90% energy savings compared with conventional lamps. CorePro Glass LED bulbs provide excellent quality of light for stairway lighting. The LED candle bulb offers a lifetime of 15,000 hours to reduce maintenance costs.

Product data


General information		Stroboscopic effect	
Lighting Technology	LED		0.4
Flux measurement reference	Sphere	Operating and electrical	
Switching Cycle	20,000	Line Frequency	50 to 60 Hz
Nominal lifetime	15,000 h	Input frequency	50 to 60 Hz
Cap base	E14 [E14]	Power Consumption	2 W
Light technical		Lamp current (nom.)	20 mA
Colour Code	827 [CCT of 2700K]	Wattage equivalent	25 W
Luminous Flux	250 lm	Starting time (nom.)	0.5 s
Colour designation	Warm White (WW)	Warm-up time to 60% light	0.5 s
Correlated Colour Temperature	2700 K	Power Factor (Fraction)	0.4
Luminous Efficacy (rated) (Nom)	125.00 lm/W	Voltage (nom.)	220-240 V
Colour consistency	<6	Temperature	
Colour rendering index (CRI)	80	T-Case maximum (nom.)	36 °C
LLMF at end of nominal lifetime (nom.)	70 %		
Flickering value (PstLM)	1		

CorePro GLASS LED candles and lustres

Controls and dimming	
Dimmable	No
Mechanical and housing	
Lamp Finish	Clear
Bulb shape	B35 [B 35 mm]
Approval and application	
Energy Efficiency Class	E
Energy-saving product	Yes
Suitable for accent lighting	No
Energy consumption kWh/1,000 hours	2 kWh
EPREL registration number	387351
CE mark	Yes



EU RoHS compliant	Yes
Product data	
Full EOC	871951437757800
Order product name	CorePro LEDCandleND 2-25W E14B35 827CL G
Order code	37757800
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929001238392
Full product name	CorePro LEDCandleND 2-25W E14B35 827CL G
EAN/UPC – Case	8719514377585

Dimensional drawing

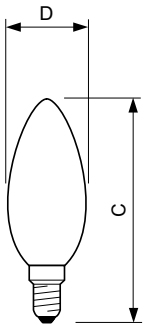

Product	D	C
CorePro LEDCandleND 2-25W E14B35 827CL G	35 mm	97 mm

Photometric data

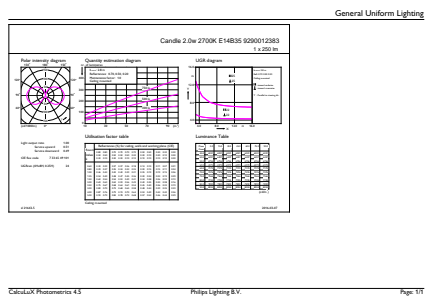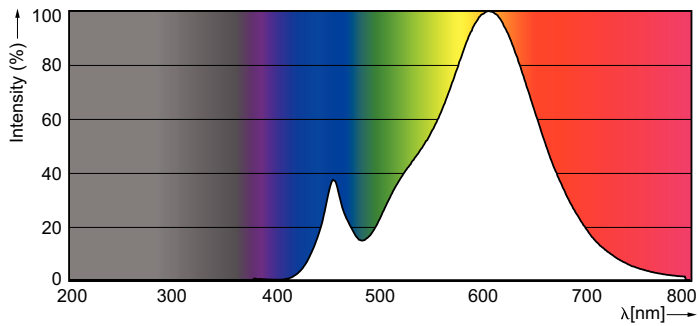


Spectral Power Distribution Colour - CorePro LEDCandleND 2-25W E14B35 827CL G

General uniform lighting - CorePro LEDCandleND 2-25W E14B35 827CL G


CorePro GLASS LED candles and lustres

Photometric data

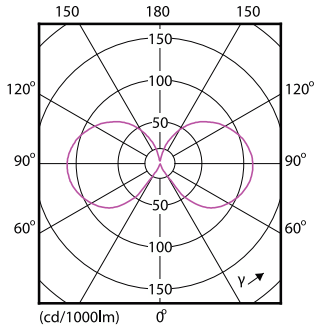


Light Distribution Diagram - CorePro LEDCandleND 2-25W E14B35 827CL G

Lifetime

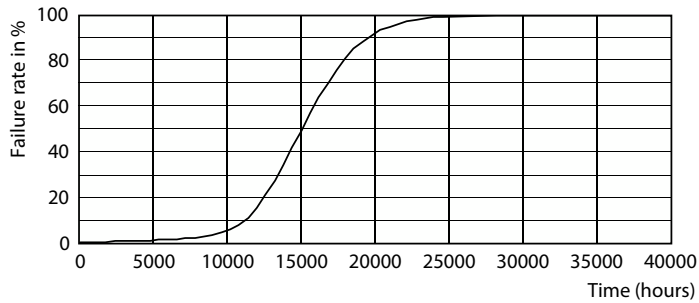

Life Expectancy Diagram - CorePro LEDCandleND 2-25W E14B35 827CL G

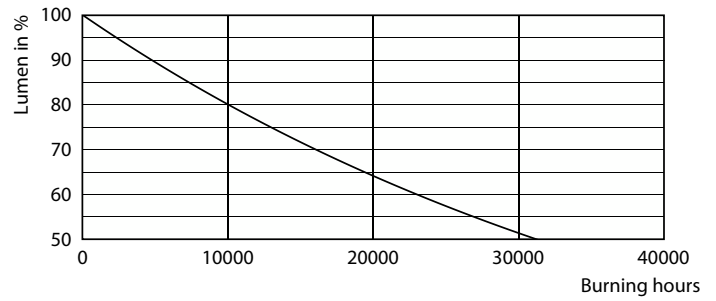

Lumen Maintenance Diagram - CorePro LEDCandleND 2-25W E14B35 827CL G

