



CorePro GLASS LED candles and lustres

CoreProLED CandleND4.3-40WE14 827B35CLGUK

Featuring a classic heritage design, these filament LED candles combine the familiar shapes of classic incandescent bulbs with the benefits of long-lasting LED technology. The LED candle bulb is a very easy choice for people who are looking for a retrofit LED replacement, it provides 90% energy savings compared with conventional lamps. CorePro Glass LED bulbs provide excellent quality of light for stairway lighting. The LED candle bulb offers a lifetime of 15,000 hours to reduce maintenance costs.

Product data

General information		Stroboscopic effect	
Lighting Technology	LED		0.4
Switching Cycle	20,000	Operating and electrical	
Nominal lifetime	15,000 h	Line Frequency	50 to 60 Hz
Cap base	E14 [E14]	Input frequency	50 to 60 Hz
Light technical		Power Consumption	4.3 W
Colour Code	827 [CCT of 2700K]	Lamp current (nom.)	40 mA
Luminous Flux	470 lm	Wattage equivalent	40 W
Colour designation	Warm White (WW)	Starting time (nom.)	0.5 s
Correlated Colour Temperature	2700 K	Warm-up time to 60% light	0.5 s
Luminous Efficacy (rated) (Nom)	109.00 lm/W	Power Factor (Fraction)	0.41
Colour consistency	<6	Voltage (nom.)	220-240 V
Colour rendering index (CRI)	80	Temperature	
LLMF at end of nominal lifetime (nom.)	70 %	T-Case maximum (nom.)	45 °C
Flickering value (PstLM)	1		

CorePro GLASS LED candles and lustres

Controls and dimming

Dimmable No

Mechanical and housing

Lamp Finish Clear

Bulb shape B35 [B 35 mm]

Approval and application

Energy Efficiency Class F

Energy consumption kWh/1,000 hours 5 kWh

EPREL registration number 387402

EU RoHS compliant Yes

Product data

Full EOC 871951434726701

Order product name CoreProLEDCandleND4.3-40WE14 827B35CLGUK

Order code 34726701

SAP numerator – quantity per pack 1


Numerator – packs per outer box 10

Material number (12NC) 929001889719

Full product name CoreProLEDCandleND4.3-40WE14 827B35CLGUK


EAN/UPC – Case 8719514406063

Dimensional drawing

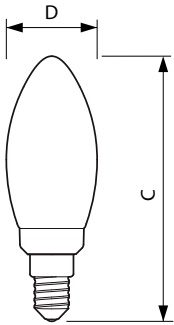


Product	D	C
CoreProLEDCandleND4.3-40WE14 827B35CLGUK	35 mm	97 mm

Photometric data

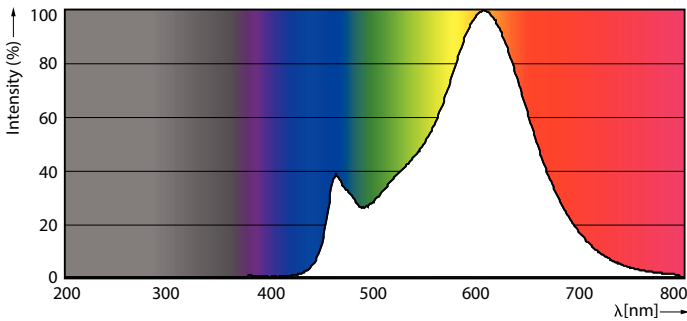


Spectral Power Distribution Colour - CoreProLEDCandleND4.3-40WE14 827B35CLGUK

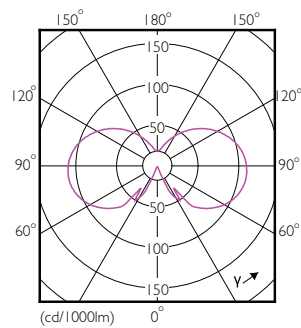

Light Distribution Diagram - CoreProLEDCandleND4.3-40WE14 827B35CLGUK


CorePro GLASS LED candles and lustres

Photometric data

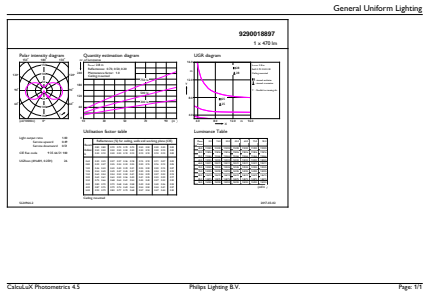

General uniform lighting - CoreProLEDCandleND4.3-40WE14 827B35CLGUK

Lifetime

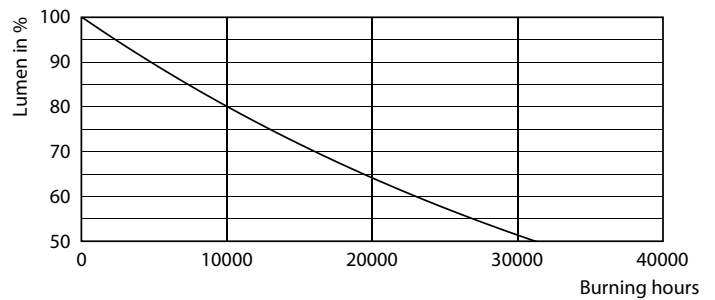

Life Expectancy Diagram - CoreProLEDCandleND4.3-40WE14 827B35CLGUK

Lumen Maintenance Diagram - CoreProLEDCandleND4.3-40WE14 827B35CLGUK

