




**Replacement Tips**  
Item: [5-CB-SA-RT](#)

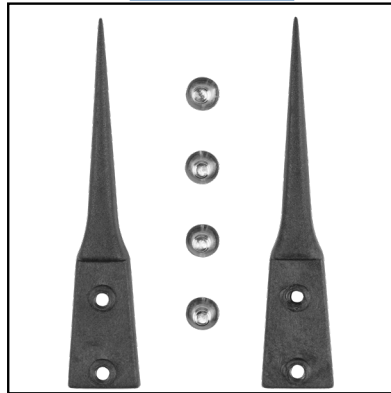

**Features:**

- **International Style:** 5
- **Handle Material:** Stainless Steel
  - **Magnetic Properties:** Anti-Magnetic
  - **Corrosion Resistance:** Anti-Acid
  - **Finish:** Polished
- **Tips:** Replaceable Carbon Fiber, Extra Taper, Very Fine
  - **Material:** Polyamide 66 with carbon fiber, Black
  - **Resistance:**
    - Tip to Tip:  $< 1 \times 10^4$  ohms tested per ANSI/ESD STM11.12
- Made in Switzerland

**Tip Specifications:**

Test	Norm	Unit	Value
Density	ISO 1183	g/cm <sup>3</sup>	1,28
Tensile strength	ISO 527	MPa	210
Elongation at break	ISO 527	%	2,5
Flexural Modulus	ISO 527	MPa	17000
Heat distribution Temperature	ASTM D 648	°C	95°
Melting point	ASTM D1525	°C	>260°
Charpy impact strength	DIN 53453	kJ/m <sup>2</sup>	30

Unless otherwise noted, tolerance is  $\pm 10\%$ .

Specifications and procedures subject to change without notice.

**PRECISION STAINLESS STEEL TWEEZER W/ REPLACEABLE CARBON FIBER TIPS, EXTRA TAPER TIP, VERY FINE, STYLE 5**

**TRONEX**

2860 CORDELIA RD STE 230, FAIRFIELD CA, 94534  
PHONE: (909) 627-2453  
WEBSITE: [TronexTools.com](http://TronexTools.com)

**DRAWING NUMBER**  
5-CB-SA-CH

**DATE**  
June 2023