



Circular Connectors M16

with Crimp Contacts

Circular connectors with threaded joint


empty housing for crimp contacts, IP40/IP68, M16

- Poles: 3–8
- Contact: gold-plated
- Connectable wire section: 0.75 mm²
- Rated current: 5 A
- Rated voltage according to pin configuration: 300 V/100 V

0369 V109 · 0364 V109

Crimp contacts, gold-plated

0369 V109 pin
0364 V109 bush

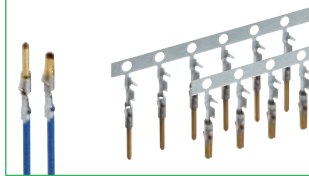

Harnessing equipment

Manual or automatic



NEW

IP40

SV ... C

Plug, straight



WSV ... C

Plug, angular



SFV ... C · SGV ... C

Chassis plugs

SFV ... C for front mounting

SGV ... C for rear mounting
in preparation



KV ... C

Socket, straight



WKV ... C

Socket, angular



KFV ... C · KGV ... C

Chassis sockets

KFV ... C for front mounting

KGV ... C for rear mounting
in preparation



IP68

0365 · 036500

Plugs, 360° shielded

036500 optimized assembly,
with vibration protection



0360 · 036000

Sockets, 360° shielded

036000 optimized assembly,
with vibration protection



0362 · 0363 · 036297

Chassis sockets

0362 for front mounting

0363 for rear mounting

036297 flange chassis socket

