


Standard Adjustable Type

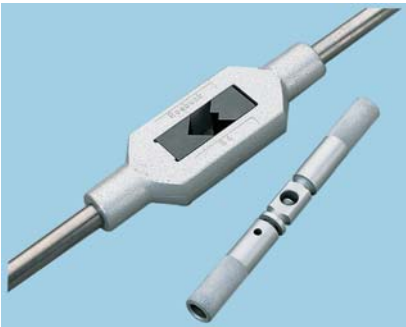

Model	Capacity		Order Code	Price Each
	(in)	(mm)		
S1	1/32 - 3/8	1 - 8	147-1917	
S1.5	1/32 - 1/2	1 - 12	147-1918	
S2	9/32 - 1/2	4 - 12	147-1913	
S3	7/32 - 3/4	5 - 20	147-1914	
S4	7/16 - 1	11 - 27	147-1915	
S6	3/4 - 1 1/2	20 - 42	147-1916	

Bar Type

506084

Model	Capacity		Order Code	Price Each
	(in)	(mm)		
B1	1/16 - 1/4	2 - 6	147-1919	
B2	1/8 - 1/2	3 - 12	147-1920	