




Part Number : [430200600](#)

Product Description : Micro-Fit 3.0 Plug Housing, Dual Row, 6 Circuits, UL 94V-0, Panel Mount Ears, Low-Halogen, Black

Series Number : 43020

Status : Active

Product Category : Connector Housings

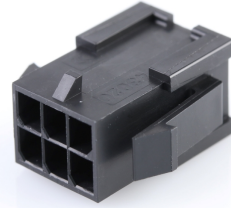

Documents & Resources

Drawings

[Drawing 430200600_sd.pdf](#)

3D Models and Design Files

[3D Model PDF 430200600.pdf](#)

[3D Model 430200600_stp.zip](#)

Specifications

[Packaging Specification PK-43020-001-001.pdf](#)

[Product Specification 430450001-PS-KO-000.pdf](#)

[Product Specification 430450001-PS-SP-000.pdf](#)

[Product Specification PS-43045-001.pdf](#)

[Test Summary 430450005-TS-000.pdf](#)


[Test Summary TS-43045-001-001.pdf](#)

[Test Summary TS-43045-003-001.pdf](#)

[Test Summary TS-46235-001-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant per EU 2015/863

[Multiple Part Product Compliance Statements](#)

- Eu RoHS

- REACH SVHC

- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C

- IPC 1752A Class D

- Molex Product Compliance Declaration

- IEC-62474

- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Connector Housings
Series	43020
Description	Micro-Fit 3.0 Plug Housing, Dual Row, 6 Circuits, UL 94V-0, Panel Mount Ears, Low-Halogen, Black
Application	Power, Wire-to-Wire
Product Family	Micro-Fit Connector System
Product Name	Micro-Fit 3.0
UPC	800754383356

Agency

CSA	LR19980
UL	E29179

Physical

Circuits (maximum)	6
Color - Resin	Black
Flammability	94V-0
Gender	Plug
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon

Net Weight	0.912/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	3.00mm
Pitch - Termination Interface	3.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

Mates With / Use With

Mates with Part(s)

Description	Part Number
Micro-Fit 3.0 Dual Row Receptacle Housings	<u>43025</u>
Micro-Fit 3.0 Female-to-Micro-Fit 3.0 Female Off-the-Shelf (OTS) Cable Assemblies	<u>214755</u>
Micro-Fit 3.0 Female-to-Pigtail Off-the-Shelf (OTS) Cable Assemblies	<u>214756</u>
Micro-fit 3.0-to-Micro-Fit 3.0 Off-the-Shelf (OTS) Overmolded Adapters and Cable Assemblies	<u>245132</u>
Micro-Fit TPA-to-Micro-Fit TPA Off-the-Shelf (OTS) Cable Assemblies	<u>45132</u>

Use with Part(s)

Description	Part Number
Micro-Fit Male Crimp Terminals	<u>43031</u>
Pre-Crimped Lead Micro-Fit 3.0 Male-to-Micro-Fit 3.0 Male	<u>214762</u>
Pre-Crimped Lead Micro-Fit 3.0 Male-to-Pigtail	<u>214763</u>
