


Mod. 5833.B

COPOLYMER POLYPROPYLENE WATERPROOF CASE

Water resistant trolley cases. Telescopic handle with quick and safe lock/unlock system and self oiling wheels. Available in black, orange and military green standard colors.



METRIC MM-KG-C°

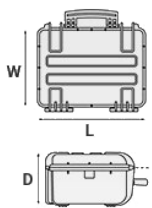

INTERNAL DIMENSIONS

L LENGTH	580 mm
W WIDTH	440 mm
D DEPTH	330 mm
LID	60 mm
BASE	270 mm


EXTERNAL DIMENSIONS

L LENGTH	670 mm
W WIDTH	510 mm
D DEPTH	372 mm

OTHER DATA

WEIGHT EMPTY	10.54 Kg
WEIGHT WITH FOAM	12.65 Kg
WEIGHT WITH CUSTOM FOAM	Kg
VOLUME	84.20 lt
BUOYANCY	62 Kg/max
OPERATING TEMPERATURE	°C min -33 / max +90

IMPERIAL IN-LBS-F°

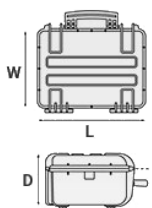

INTERNAL DIMENSIONS

L LENGTH	22 13/16 in
W WIDTH	17 5/16 in
D DEPTH	13 in
LID	2 3/8 in
BASE	10 5/8 in

EXTERNAL DIMENSIONS

L LENGTH	26 3/8 in
W WIDTH	20 1/16 in
D DEPTH	14 5/8 in

OTHER DATA

WEIGHT EMPTY	23.23 lbs
WEIGHT WITH FOAM	27.88 lbs
WEIGHT WITH CUSTOM FOAM	lbs
VOLUME	22.19 gal
BUOYANCY	136.68 lbs/max
OPERATING TEMPERATURE	°F min -27.4 / max +194