


PXM6010/04P/CR/0709 Datasheet

Product Name // Flex Cable Connector PXM6010 Series 4
Contact Plug Crimp/Solder Termination (contacts available
separately) 7mm-9mm Cable (Yellow Gland) Metal Body No
Braid Termination

 [View Product Page](#)

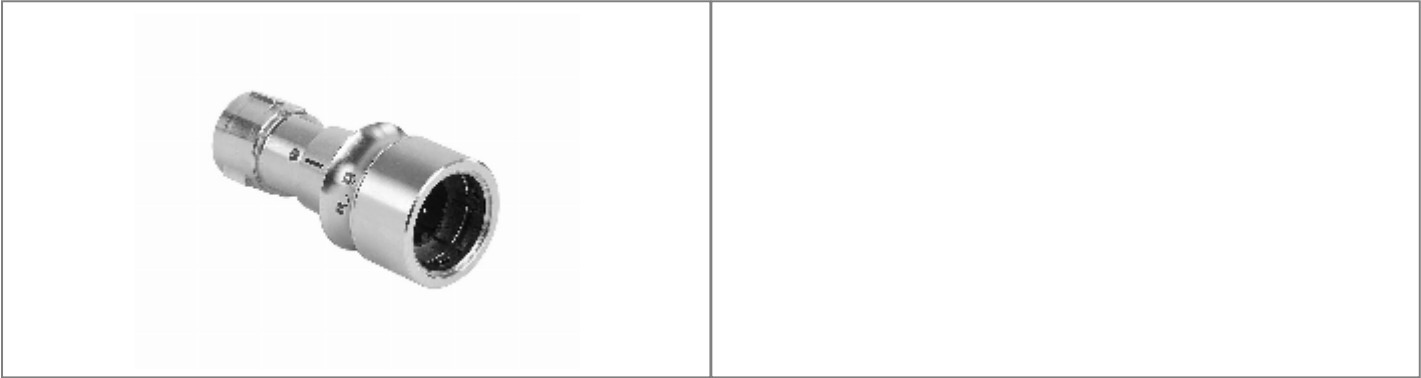

// Product Description:



Flex Cable Connectors



Water and dustproof to IP66, IP68, IP69K when mated with compatible connector



30 degree push twist locking, tamperproof lock prevents accidental un-mating



Plug



4 Contacts



Crimp/solder termination with contacts and fitting tool available separately



Metal Body No Braid Termination



Cable acceptance 7mm-9mm diameter



Gland Pack PXP6088 available separately to accomodate all sizes



PXM6081 Sealing Cap available separately to maintain IP rating of unmated connectors



Mate with PXM6011 Series Inline and PXM6012 Series Front Panel Mount Connectors

// General Information:

Product Display Title:

Product Family:

Product Series:

Body Colour:

Body Material:

Body Material Type:

Contact Type:

Coupling Type:

Current Max:

Diameter Over Coupling Ring Mm:

Function:

Insulation Resistance:

Ip Rating:

Max Cable Entry Size:

Min Cable Entry Size:

Max Contact Accomodation Awg:

Min Contact Accomodation Awg:

Max Contact Accomodation Mm2:

Min Contact Accomodation Mm2:

Max Operating Temperature:

Min Operating Temperature:

Number Of Contacts:

Rohs Compliant:

Salt Spray Corrosion Test:

Voltage Max:

Flex Cable Connectors

Circular Power Connectors

6000 Series Buccaneer

Metallic Grey

Brass

Metal Body No Braid Termination

Plug Contact

Push-Twist

10A, 4A, 7A

32mm

Flex Cable Connector

>10⁶MΩ @500V DC

IP66, IP68, IP69K

9mm

7mm

20AWG

16AWG

1.5mm2

0.5mm2

+120°C

-40°C

4 Contacts

Yes

EN60068-2-11 Test Ka Salt Mist

277V

// Product PDF Links

 6000 Series power connectors...

 6000 Series metal body power...

// Product 3D CAD Model Links

 PXM6010/04P/CR/07093D CAD Model