


# NSYTBS16128T

ABS box IP66 IK07 RAL7035  
Int.H150W105D80 Ext.H164W121D87  
Transp.cover H20

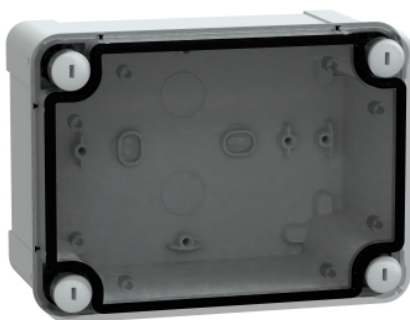

## Main

Range	Thalassa
Product name	Thalassa TBS
Device Application	Multi-purpose
Category	Industrial box
Height	6.46 in (164 mm)
Width	4.76 in (121 mm)
Depth	3.43 in (87 mm)
Internal height	5.91 in (150 mm)
Internal width	4.13 in (105 mm)
Internal depth	3.15 in (80 mm)
Enclosure mounting	Wall mounted
Device composition	1 body 1 cover 4 cover screw
Quantity per Set	Set of 2
Body type	One piece moulded
Type of front cover	Low transparent cover
Cover fixing	Plastic screws
Lock type	Captive screw flat outside sealed area
Removable parts	Cover by captive screws

## Complementary

Material	ABS (acrylonitrile butadiene-styrene)
Color	Gray RAL 7035) Transparent
Standards	IEC 62208
Product Certifications	TÜV
Electrical Insulation Class	Class II
IP degree of protection	IP66 conforming to NEMA 4.4X
IK degree of protection	IK07 IEC 62262
Glow wire resistance	1202 °F (650 °C) IEC 60695-2-11
Ambient Air Temperature for Storage	5...104 °F (-15...40 °C)
Operating temperature	-13...140 °F (-25...60 °C)
Product Weight	0.75 lb(US) (0.34 kg)

## Ordering and shipping details

Category	80033-ENCLOSURE SYSTEMS POLYESTER
Discount Schedule	ES1
GTIN	3606480165436
Returnability	No
Country of origin	HU

## Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3.43 in (8.7 cm)
Package 1 Width	4.76 in (12.1 cm)
Package 1 Length	6.46 in (16.4 cm)
Package 1 Weight	11.99 oz (340 g)

## Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	<a href="#"> REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#"> EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	<a href="#"> China RoHS Declaration</a>
RoHS exemption information	<a href="#"> Yes</a>
Environmental Disclosure	<a href="#"> Product Environmental Profile</a>

## Contractual warranty

Warranty	18 months
----------	-----------