


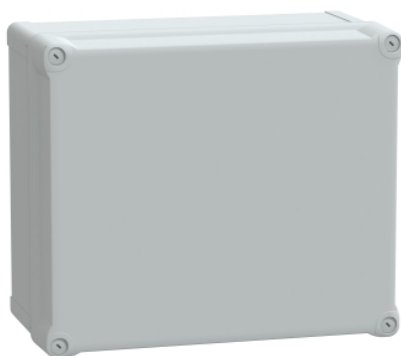

Main

Range	Thalassa
Product name	Thalassa TBP
Device Application	Multi-purpose
Category	Industrial box
Height	13.43 in (341 mm)
Width	11.46 in (291 mm)
Depth	6.61 in (168 mm)
Internal height	12.80 in (325 mm)
Internal width	10.83 in (275 mm)
Internal depth	6.30 in (160 mm)
Enclosure mounting	Wall mounted
Device composition	1 body 1 cover 4 cover screw
Body type	One piece moulded
Type of front cover	High plain cover
Cover fixing	Plastic screws
Lock type	Captive screw flat outside sealed area
Removable parts	Cover by captive screws

Complementary

Material	polycarbonate
Color	Gray RAL 7035)
Standards	IEC 62208 UL 508 A
Product Certifications	TÜV UL
Electrical Insulation Class	Class II
Mounting location	Outdoor (with canopy or shelter and anticondensation valve)
Product Weight	3.66 lb(US) (1.66 kg)

Environment

IP degree of protection	IP66 conforming to NEMA 4.4X
IK degree of protection	IK08 IEC 62262
Fire resistance	1760 °F (960 °C)
Ambient Air Temperature for Storage	5...140 °F (-15...60 °C)
Operating temperature	-13...176 °F (-25...80 °C)

Ordering and shipping details

Category	80033-ENCLOSURE SYSTEMS POLYESTER
Discount Schedule	ES1
GTIN	3606480165771
Returnability	No
Country of origin	HU

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.28 in (18.5 cm)
Package 1 Width	11.81 in (30.0 cm)
Package 1 Length	14.17 in (36.0 cm)
Package 1 Weight	4.20 lb(US) (1.906 kg)
Unit Type of Package 2	CAR
Number of Units in Package 2	3
Package 2 Height	15.94 in (40.5 cm)
Package 2 Width	15.75 in (40.0 cm)
Package 2 Length	23.62 in (60.0 cm)
Package 2 Weight	14.60 lb(US) (6.624 kg)
Unit Type of Package 3	PAM
Number of Units in Package 3	75
Package 3 Height	86.61 in (220.0 cm)
Package 3 Width	39.37 in (100.0 cm)
Package 3 Length	47.24 in (120.0 cm)
Package 3 Weight	394.63 lb(US) (179.0 kg)

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	 REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope)  EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	 China RoHS Declaration
RoHS exemption information	 Yes
Environmental Disclosure	 Product Environmental Profile
Circularity Profile	 End Of Life Information

Contractual warranty

Warranty	18 months
----------	-----------