


Product data sheet

Characteristics

NSYTBP292416H
PC box IP66 IK08 RAL7035
Int.H275W225D160 Ext.H291W241D168
opaque PC cover H60

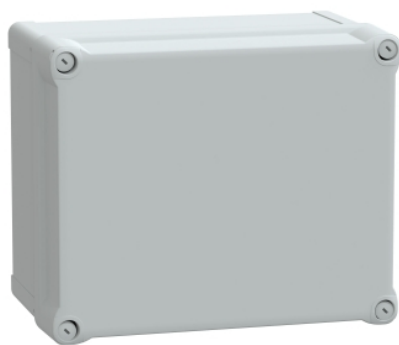

Main

Range	Thalassa
Product name	Thalassa TBP
Device Application	Multi-purpose
Category	Industrial box
Height	11.46 in (291 mm)
Width	9.49 in (241 mm)
Depth	6.61 in (168 mm)
Internal height	10.83 in (275 mm)
Internal width	8.86 in (225 mm)
Internal depth	6.30 in (160 mm)
Enclosure mounting	Wall mounted
Device composition	1 body 1 cover 4 cover screw
Body type	One piece moulded
Type of front cover	High plain cover
Cover fixing	Plastic screws
Lock type	Captive screw flat outside sealed area
Removable parts	Cover by captive screws

Complementary

Material	polycarbonate
Color	Gray RAL 7035)
Standards	IEC 62208 UL 508 A
Product Certifications	TÜV UL
Electrical Insulation Class	Class II
Mounting location	Outdoor (with canopy or shelter and anticondensation valve)
Product Weight	2.73 lb(US) (1.24 kg)

Environment

IP degree of protection	IP66 conforming to NEMA 4.4X
IK degree of protection	IK08 IEC 62262
Fire resistance	1760 °F (960 °C)
Ambient Air Temperature for Storage	5...140 °F (-15...60 °C)
Operating temperature	-13...176 °F (-25...80 °C)

Ordering and shipping details

Category	80033-ENCLOSURE SYSTEMS POLYESTER
Discount Schedule	ES1
GTIN	3606480165757
Returnability	Yes
Country of origin	HU

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	7.09 in (18 cm)
Package 1 Width	9.84 in (25 cm)
Package 1 Length	12.20 in (31 cm)
Package 1 Weight	3.01 lb(US) (1.367 kg)
Unit Type of Package 2	CAR
Number of Units in Package 2	4
Package 2 Height	15.75 in (40 cm)
Package 2 Width	15.75 in (40 cm)
Package 2 Length	23.62 in (60 cm)
Package 2 Weight	14.51 lb(US) (6.58 kg)
Unit Type of Package 3	PAM
Number of Units in Package 3	100
Package 3 Height	86.61 in (220 cm)
Package 3 Width	39.37 in (100 cm)
Package 3 Length	47.24 in (120 cm)
Package 3 Weight	392.42 lb(US) (178 kg)

Offer Sustainability

Sustainable offer status	Green Premium product
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
China RoHS Regulation	China RoHS Declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End Of Life Information

Contractual warranty

Warranty	18 months
----------	-----------