


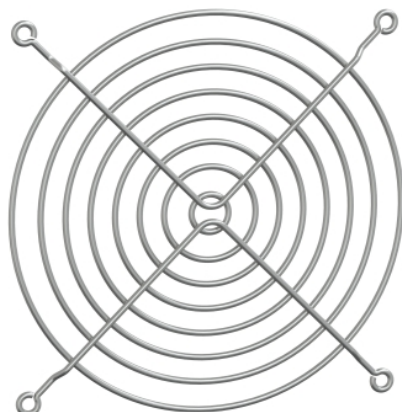

### Main

|                                       |                              |
|---------------------------------------|------------------------------|
| Range                                 | ClimaSys                     |
| Product                               | ClimaSys CV                  |
| Range compatibility                   | ClimaSys (ClimaSys CV) fan   |
| Product or Component Type             | Rear protective grille       |
| Accessory / separate part category    | Thermal management accessory |
| Accessory / separate part destination | For enclosure fan motor      |
| Mounting Location                     | Rear of axial motor          |
| Fixing Mode                           | By screws                    |
| Device composition                    | 1 protective grille          |

### Complementary

|          |                                                                |
|----------|----------------------------------------------------------------|
| Material | Steel                                                          |
| Diameter | 4.49 in (114 mm)                                               |
| Height   | External 4.72 in (120 mm)<br>Fixing centers 4.13 in (104.8 mm) |
| Width    | External 4.72 in (120 mm)<br>Fixing centers 4.13 in (104.8 mm) |

### Ordering and shipping details

|                   |                                     |
|-------------------|-------------------------------------|
| Category          | 80036-ENCLOSURE SYSTEMS ACCESSORIES |
| Discount Schedule | ES1                                 |
| GTIN              | 3606480151507                       |
| Returnability     | No                                  |
| Country of origin | ES                                  |

### Packing Units

|                              |                      |
|------------------------------|----------------------|
| Unit Type of Package 1       | PCE                  |
| Number of Units in Package 1 | 1                    |
| Package 1 Height             | 0.20 in (0.500 cm)   |
| Package 1 Width              | 6.10 in (15.500 cm)  |
| Package 1 Length             | 6.10 in (15.500 cm)  |
| Package 1 Weight             | 1.14 oz (32.300 g)   |
| Unit Type of Package 2       | BB1                  |
| Number of Units in Package 2 | 10                   |
| Package 2 Height             | 1.38 in (3.500 cm)   |
| Package 2 Width              | 6.10 in (15.500 cm)  |
| Package 2 Length             | 6.10 in (15.500 cm)  |
| Package 2 Weight             | 13.26 oz (376.000 g) |

## Offer Sustainability

|                            |                                                                                                |
|----------------------------|------------------------------------------------------------------------------------------------|
| Sustainable offer status   | Green Premium product                                                                          |
| REACH Regulation           | <a href="#">REACH Declaration</a>                                                              |
| REACH free of SVHC         | Yes                                                                                            |
| EU RoHS Directive          | Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a> |
| Mercury free               | Yes                                                                                            |
| China RoHS Regulation      | <a href="#">China RoHS Declaration</a>                                                         |
| RoHS exemption information | <a href="#">Yes</a>                                                                            |
| Environmental Disclosure   | <a href="#">Product Environmental Profile</a>                                                  |
| Circularity Profile        | <a href="#">End Of Life Information</a>                                                        |

## Contractual warranty

|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|