

Self-laminating labels, laser printer

Helatag 1104 (White-Transparent)

A specially developed material for use in labels required to wrap around cables and wires. The structure of the label ensures that once the label is applied to the wire it remains in place without lifting. The rounded edge construction gives additional bonding features not found in straight edge label designs. The information is printed onto the white inscription area. The printed information area is placed onto the wire and the transparent tail is wrapped around the wire and covers the text; this gives excellent protection from abrasion, dust and debris. TagPrint Pro labelling program comes pre-loaded with all our labels. Designing labels is simply done; just choose inbuilt graphics or download your own and add data from ERP system or standard office programs such as Excel. Barcodes are created in a couple of clicks.




Laminating the mark gives long-term print survivability.

Features and benefits

- High-quality self-laminating labels
- Suitable for marking of wires and cables
- Laminating function gives excellent protection against humidity and mechanical abrasion
- Rounded edge design gives additional bonding strength
- Standard material (25 micron) for standard labels
- Simple and efficient label design and printing with TagPrint Pro labelling software
- Templates available from www.HellermannTyton.com/templates for those wishing to use MS Word
- Clear protective box to ensure labels stay as good as new

MATERIAL	Type 1104, Polyester, white transparent, self-laminating (1104)
Operating Temperature	-40 °C to +150 °C
Curing Temperature	from +10 °C
Adhesive	Acrylic
Thickness of Foil	25 µm
Chem. Material Properties	Excellent resistance to alcohol, gasoline, cleaning solvents, butanol, ethyl and Butylcellosolve solvent, battery acid.

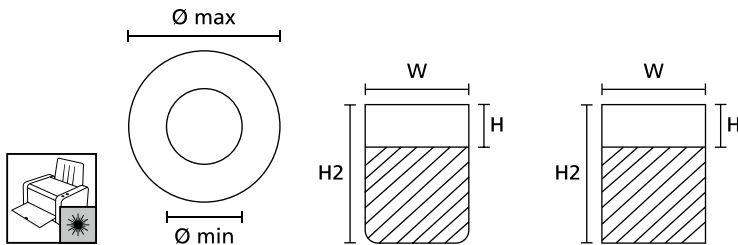

Only 594-11041 and 594-11040



Software TagPrint Pro for troublefree printing see page 526. For MS-Windows Word design templates for simple applications please refer to www.HellermannTyton.com/templates.

TYPE	Bundle Ø min.	Bundle Ø max.	Width (W)	Height (H)	Height (H2)	Labels per Sheet	Pack Cont.	Colour	Article-No.
TAG26LA4-1104-WHCL	1.5	3.0	12.7	9.5	19.1	180 pcs.	5,000 pcs.	White (WH), Transparent (CL)	594-11041
TAG130LA4-1104-WHCL	2.4	4.8	12.7	9.0	24.0	165 pcs.	5,000 pcs.	White (WH), Transparent (CL)	594-21104
TAG49LA4-1104-WHCL	2.6	5.3	25.4	8.8	25.4	70 pcs.	2,500 pcs.	White (WH), Transparent (CL)	594-11042
TAG131LA4-1104-WHCL	3.8	7.6	12.7	12.7	36.5	105 pcs.	2,500 pcs.	White (WH), Transparent (CL)	594-31104
TAG132LA4-1104-WHCL	3.8	7.6	20.3	12.7	36.5	63 pcs.	2,500 pcs.	White (WH), Transparent (CL)	594-41104
TAG02LA4-1104-WHCL	3.8	7.6	25.4	12.7	36.5	49 pcs.	2,450 pcs.	White (WH), Transparent (CL)	594-01104
TAG133LA4-1104-WHCL	5.1	10.1	19.1	12.7	44.5	60 pcs.	2,500 pcs.	White (WH), Transparent (CL)	594-51104
TAG134LA4-1104-WHCL	5.1	10.1	25.4	12.7	44.5	42 pcs.	1,000 pcs.	White (WH), Transparent (CL)	594-61104
TAG09LA4-1104-WHCL	5.8	11.6	25.4	19.1	55.5	35 pcs.	1,000 pcs.	White (WH), Transparent (CL)	594-11104
TAG135LA4-1104-WHCL	6.7	13.5	48.5	12.7	55.0	20 pcs.	500 pcs.	White (WH), Transparent (CL)	594-71104
TAG137LA4-1104-WHCL	7.1	14.3	31.8	22.9	67.7	24 pcs.	1,000 pcs.	White (WH), Transparent (CL)	594-91104
TAG136LA4-1104-WHCL	7.7	15.5	25.4	19.1	67.7	28 pcs.	1,000 pcs.	White (WH), Transparent (CL)	594-81104
TAG145LA4-1104-WHCL	11.1	22.3	25.4	25.4	95.3	21 pcs.	1,000 pcs.	White (WH), Transparent (CL)	594-11040

All dimensions in mm. Subject to technical changes. Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.



For product specific approvals and specifications please refer to the Appendix.

