


Part Number: 1904X00XWE

Type	Size	Rating	Description
LED	M8	No Res	LED Panel Mount Indicator Prominent with Leads

Dimensions in mm (Not to scale)

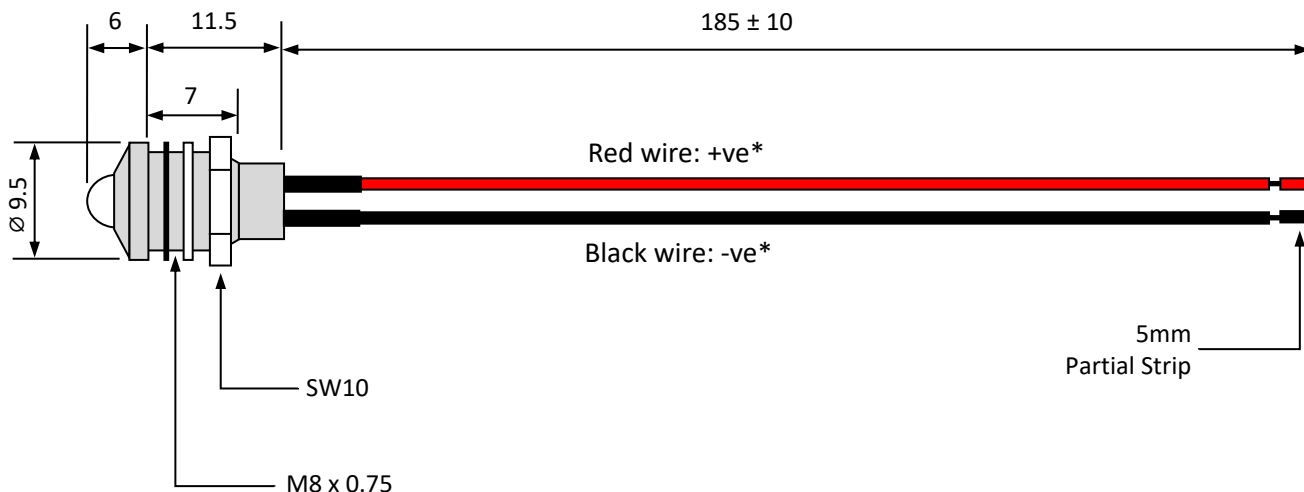

Part Number	Colour	Typ Vf	Typ. Luminous Intensity (mcd @ 10mA)
1904x003WE	Red	2.0	25
1904x001WE	Green	2.2	20
1904x007WE	Blue	3.8	45
1904x004WE	Red/Green*	2.0/2.2*	15/15*

x = 0: Satin chrome bezel

Notes:

- 1 Electrical & optical data are measured at an ambient temperature of 25°C
- 2 The stated luminous intensity is for dc operation
- 3 Due to component tolerances, colour temperature variations may be observed
- 4 Storage temperature range: -25 °C to +80°C
- 5 Operating temperature range: -20 °C to +60°C
- 6 The plastic (polycarbonate) has limited chemical resistance
- 7 Lead wires are externally soldered
- 8 Lead wires: 7/0.2 (24 AWG) stranded copper, tinned annealed copper wire, PVC insulation
- 9 REACH SVHC compliant
- 10 This product contains free-machining brass and is RoHS compliant via exemption clause Annex iii 6 (c) of EU Directive 2011/65/EU [Copper alloy containing lead up to 4% by weight]
- 11\* The Red/Green variant illuminates Red when Red wire + Black wire – and Green when Red wire – Black wire +.