


Part Number: 1904XX0XWE

| Type | Size | Description |
|------|------|--|
| LED | M8 | LED Panel Mount Indicator Prominent with Leads |

Dimensions in mm (Not to scale)

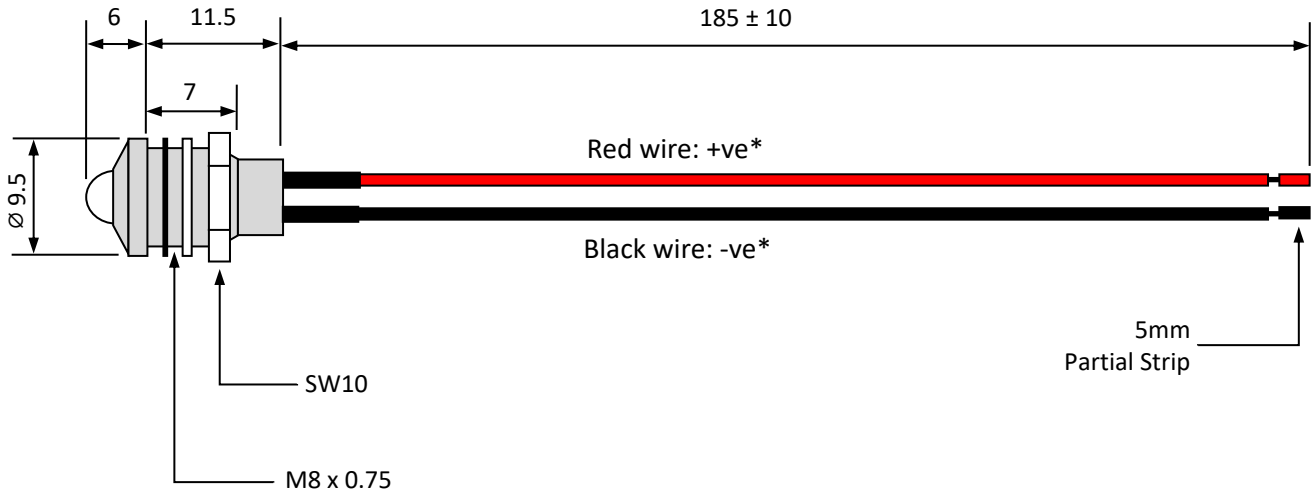

| Part Number | Colour | Rating (V) | Typ Current (mA) | Typ Intensity (mcd) |
|-------------|------------|------------|------------------|---------------------|
| 1904x203WE | Red | 12 | 16 | 40 |
| 1904x201WE | Green | 12 | 16 | 32 |
| 1904x207WE | Blue | 12 | 16 | 72 |
| 1904x204WE | Red/Green* | 12 | 25/25 | 37/37 |
| 1904x303WE | Red | 24 | 22 | 55 |
| 1904x301WE | Green | 24 | 22 | 44 |
| 1904x307WE | Blue | 24 | 20 | 90 |
| 1904x304WE | Red/Green* | 24* | 22/22 | 33/33 |

x = 0: Satin chrome bezel

Notes:

- 1 Electrical & optical data are measured at an ambient temperature of 25°C
- 2 The stated luminous intensity is for dc operation
- 3 Due to component tolerances, colour temperature variations may be observed
- 4 Storage temperature range: -25 °C to +80°C
- 5 Operating temperature range: -20 °C to +60°C
- 6 The plastic (polycarbonate) has limited chemical resistance
- 7 Lead wires are externally soldered
- 8 Lead wires: 7/0.2 (24 AWG) stranded copper, tinned annealed copper wire, PVC insulation
- 9 REACH SVHC compliant
- 10 This product contains free-machining brass and is RoHS compliant via exemption clause Annex iii 6 (c) of EU Directive 2011/65/EU [Copper alloy containing lead up to 4% by weight]
- 11* The Red/Green variant illuminates Red when Red wire + Black wire – and Green when Red wire – Black wire +.