

## Product information


# 97 52 37

**KNIPEX PreciForce®**  
Crimping Pliers


- Consistently high crimping quality thanks to precision dies and ratchet mechanism (unlockable)
- Tools have been set precisely (calibrated) in the factory
- Optimum transmission of force thanks to toggle lever for fatigue-reduced operation
- Good handling thanks to favourable handle position, low weight, compact design and ergonomically shaped handles
- Crimping die is not exchangeable
- Special quality chrome vanadium electric steel, oil-hardened




General	
Article No.	97 52 37
EAN	4003773063193
Pliers	burnished
Handles	with multi-component grips
Weight	478 g
Dimensions	220 x 70 x 21 mm
REACH compliant	contains SVHC
RoHS compliant	not applicable

Technical details	
	
Application	heat shrinkable sleeve connectors
Capacity in square millimetres	0.5 — 6.0 mm <sup>2</sup>
Number of crimping positions	3
AWG	20 — 10

*technical change and errors excepted*

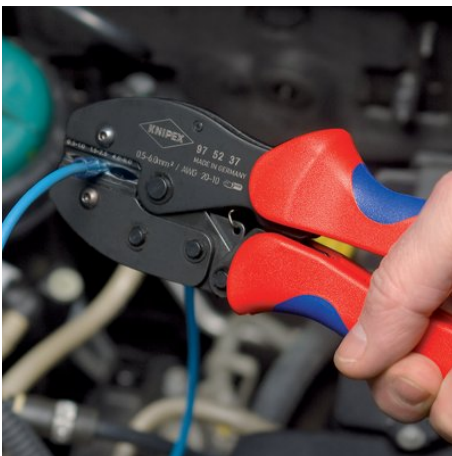

97 52 37

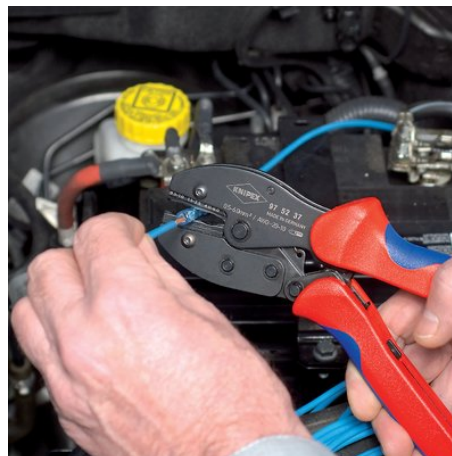

97 52 37