

Product information

22 05 160

- For bending wire loops
- Round, short jaws; finely ground
- Smooth tips
- Special tool steel, forged, oil-hardened


Round Nose Pliers

DIN ISO 5745



General	
Article No.	22 05 160
EAN	4003773042907
Pliers	chrome-plated
Head	chrome-plated
Handles	with multi-component grips
Weight	169 g
Dimensions	160 x 55 x 19 mm
Standard	DIN ISO 5745
REACH compliant	does not contain SVHC
RoHS compliant	not applicable

Technical details	
Jaw thickness (joint) (T1)	9.5 mm
Tips thickness (T2)	3.0 mm
Jaw length (L3)	30.0 mm
Head width (W3)	18 mm

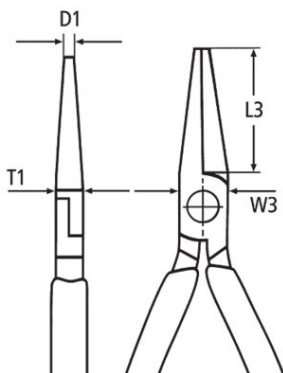

technical change and errors excepted

