




CSB-M1250M1250-T

► SPLITTERS

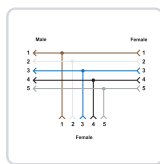

M12 T Splitter - Passive

5-Pin Female Trunk Straight

5-Pin Female T Branch (1)

5-Pin Male T Branch(1)

Black TPU Splitter Junction

Part Number: 807397

SPECIFICATIONS

IP Rating	IP67
Shield/No Shield	No Shield
Wiring	Parallel
Branches: Genders	Female, Male
Branches: Orientations	Straight, Straight
Splitter: Overmold Material and Color	PUR Black
Trunk Length (m)	0.00
Branches: Number of Contacts	5, 5
Number of Branches	2
Voltage Rating (V)	250 V ac/dc
Maximum Temp. (Celsius)	105
Current Rating (A)	4.0
Trunk: Orientation	Straight
Trunk: Number of Contacts	5
Trunk: Connector Type	M12
Trunk: Gender	Female

Minimum Temp. (Celsius)	-40
Branches: Connector Types	M12, M12



Banner Engineering Corp. | 9714 Tenth Avenue North | Minneapolis, MN 55441 |
United States of America