

## Han E-SMC-MC-GT-CRT-1.0 mm² / 18 AWG

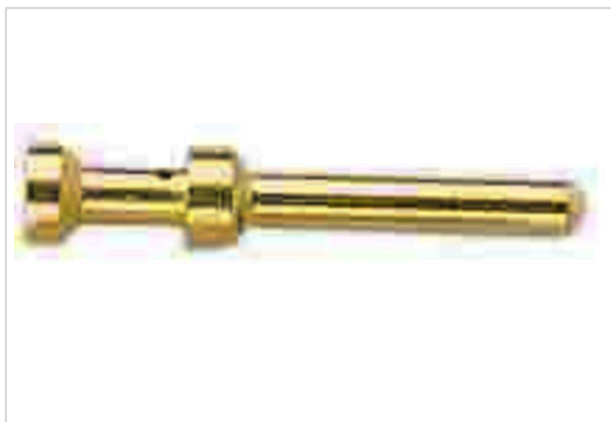


Image is for illustration purposes only. Please refer to product description.

Part number	09 33 000 6305
Specification	Han E-SMC-MC-GT-CRT-1.0 mm² / 18 AWG

### Identification

Category	Contacts
Series	Han E <sup>®</sup>
Type of contact	Crimp contact

### Version

Gender	Male
Manufacturing process	Turned contacts

### Technical characteristics

Conductor cross-section	1 mm²
Conductor cross-section	AWG 18
Rated current	≤16 A
Contact resistance	≤1 mΩ
Stripping length	7.5 mm

### Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Han <sup>®</sup> -GoldTec
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	Not contained



**Pushing Performance**  
Since 1945

## Material properties

REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	Lead
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead Nickel

## Specifications and approvals

Specifications	IEC 60664-1 IEC 61984
----------------	--------------------------

## Commercial data

Packaging size	100
Net weight	1.27 g
Country of origin	Switzerland
European customs tariff number	85366990
GTIN	5713140050181
ETIM	EC000796
eCl@ss	27440204 Contact for industrial connectors