


PXMBNI78FPM04AFL78001 Datasheet

**Product Name // 4 Contacts 7/8" Front Panel Mounting
Male 100mm Flying Leads**

[View Product Page](#)

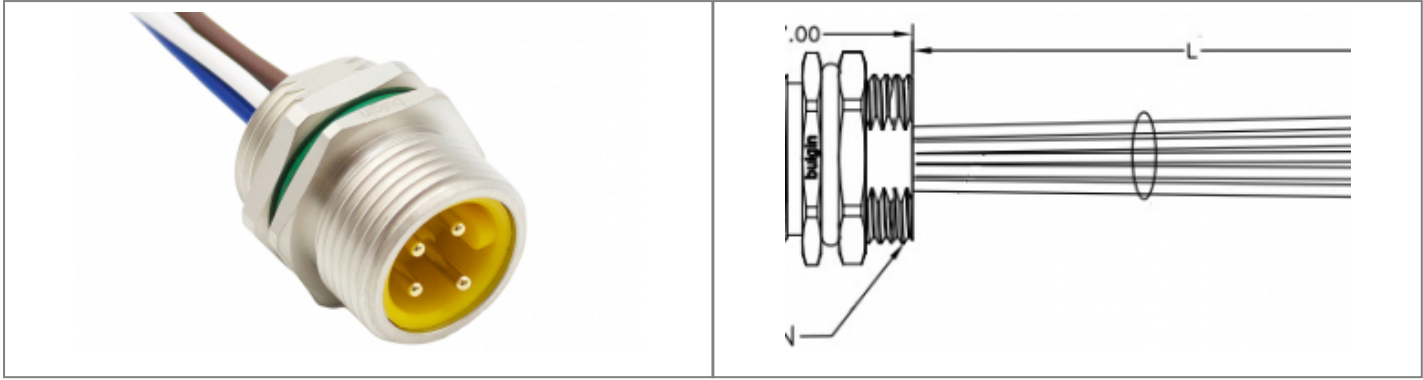

// Product Description:

- ⬡ 4 Contacts 7-8" Front Panel Mounting Male 0.1M Cable
- ⬡ IP67 rated when mated
- ⬡ Mechanical Cycles >100
- ⬡ Operating Temperature -25Â°C to +85Â°C
- ⬡ Rated Voltage 300 V
- ⬡ ROHS compliance

// General Information:

Product Display Title:	7/8" Front Panel Mounting Male 100mm Flying Leads
Product Family:	Circular Automation Connectors
Product Series:	7/8" Series
Cable Length:	0.1m
Connection Method:	Solder
Contact Type:	Plug Contact
Current Max:	8A
Durability:	>100 Cycles
Function:	Front Panel Mounting Male Connector with Flying Leads
Insulation Resistance:	>100MOhm
Ip Rating:	IP67
Max Operating Temperature:	+80°C
Min Operating Temperature:	-25°C
Number Of Contacts:	4 Contacts
Pin Layout Code:	A Code
Rohs Compliant:	Yes
Thread Size:	7/8-16UN
Voltage Max:	300V

// Product PDF Links

[78 Series Circular connectors...](#)