


PXPTPU78FIM03ACL010PUR Datasheet

Product Name // 3 Contacts 7/8" Inline Body Male 1m Cable

[View Product Page](#)

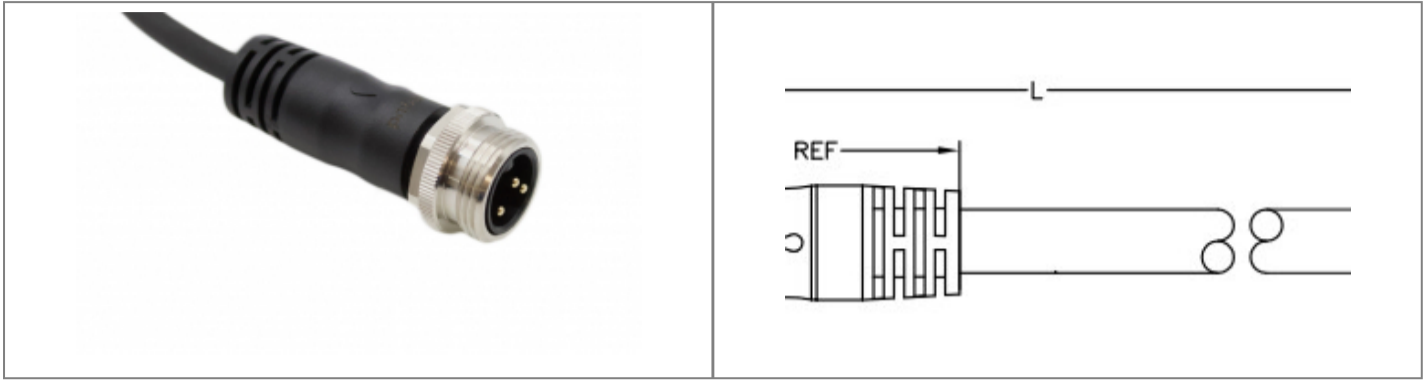

// Product Description:

- ⊕ 3 Contacts 7-8" Inline Body Male 1m Cable
- ⊕ IP67 rated when mated
- ⊕ Mechanical Cycles >100
- ⊕ Operating Temperature -25Å°C to +85Å°C
- ⊕ Rated Voltage 300 V
- ⊕ ROHS compliance

// General Information:

| | |
|----------------------------|---|
| Product Display Title: | 7/8" Inline Body Male 1m Cable |
| Product Family: | Circular Automation Connectors |
| Product Series: | 7/8" Series |
| Cable Length: | 1m |
| Connection Method: | Solder |
| Contact Type: | Plug Contact |
| Current Max: | 12A |
| Durability: | >100 Cycles |
| Function: | Inline Body Male Connector Single Ended Cable |
| Insulation Resistance: | >100MOhm |
| Ip Rating: | IP67 |
| Max Cable Entry Size: | 6.5mm |
| Max Operating Temperature: | +80°C |
| Min Operating Temperature: | -25°C |
| Number Of Contacts: | 3 Contacts |
| Pin Layout Code: | A Code |
| Rohs Compliant: | Yes |
| Thread Size: | 7/8-16UN |
| Voltage Max: | 300V |

// Product PDF Links

[78 Series Circular connectors...](#)