


PXPTPU78FIM05ACL020PUR Datasheet

bulgin

Product Name // 5 Contacts 7/8" Inline Body Male 2m Cable

 View Product Page

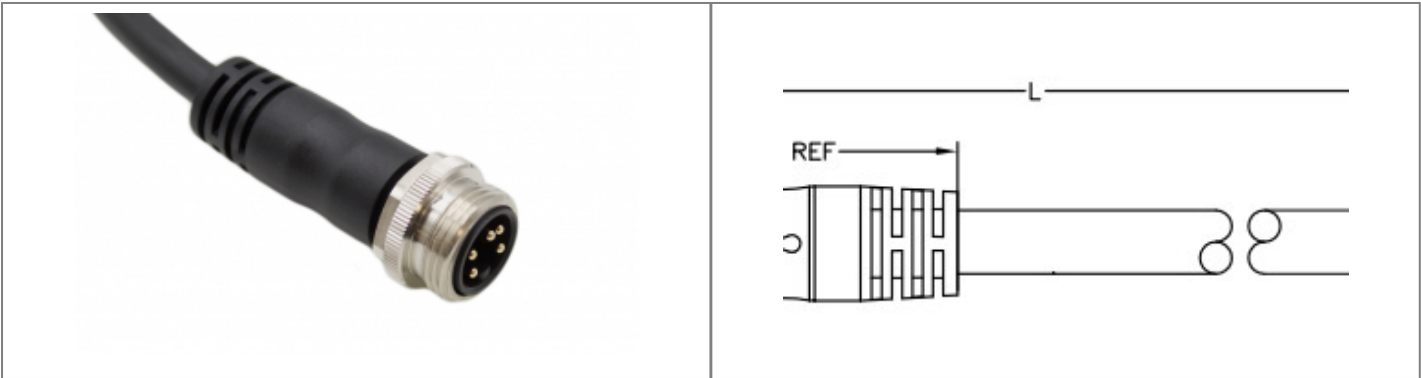

| // Product Description:                                                                                                     |                                                                                                                          |
|-----------------------------------------------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------------------------------------------|
|  3 Contacts 7-8" Inline Body Male 2m Cable |  Operating Temperature -25Â°C to +85Â°C |
|  IP67 rated when mated                    |  Rated Voltage 300 V                   |
|  Mechanical Cycles >100                  |  ROHS compliance                      |

| // General Information:    |                                               |
|----------------------------|-----------------------------------------------|
| Product Display Title:     | 7/8" Inline Body Male 2m Cable                |
| Product Family:            | Circular Automation Connectors                |
| Product Series:            | 7/8" Series                                   |
| Cable Length:              | 2m                                            |
| Connection Method:         | Solder                                        |
| Contact Type:              | Plug Contact                                  |
| Current Max:               | 9A                                            |
| Durability:                | >100 Cycles                                   |
| Function:                  | Inline Body Male Connector Single Ended Cable |
| Insulation Resistance:     | >100MOhm                                      |
| Ip Rating:                 | IP67                                          |
| Max Cable Entry Size:      | 8.5mm                                         |
| Max Operating Temperature: | +80°C                                         |
| Min Operating Temperature: | -25°C                                         |
| Number Of Contacts:        | 5 Contacts                                    |
| Pin Layout Code:           | A Code                                        |
| Rohs Compliant:            | Yes                                           |
| Thread Size:               | 7/8-16UN                                      |
| Voltage Max:               | 300V                                          |

// Product PDF Links

 78 Series Circular connectors...