

Part Number: X-2629-TWT-R



Features

Mounting: PC Mount
Tone: Continuous
Frequency: 2900 +/- 500 Hz
This part is RoHS 2002/ 95/EC Compliant


Electrical Specifications

Operating Voltage	5-14 Vdc
Rated Current (Max.)	35 mA
Rated Voltage	12 Vdc
Resonant Frequency	2900 +/- 500 Hz
Sound Pressure Level @ 10 cm (Min.)	107 dBA

Case Material: PC
Weight: 12g
Pin Material: Sn Plated Copper
Environmentally friendly


Mechanical

Dimensions are in millimeters, tolerance is ± 0.5 unless otherwise specified.

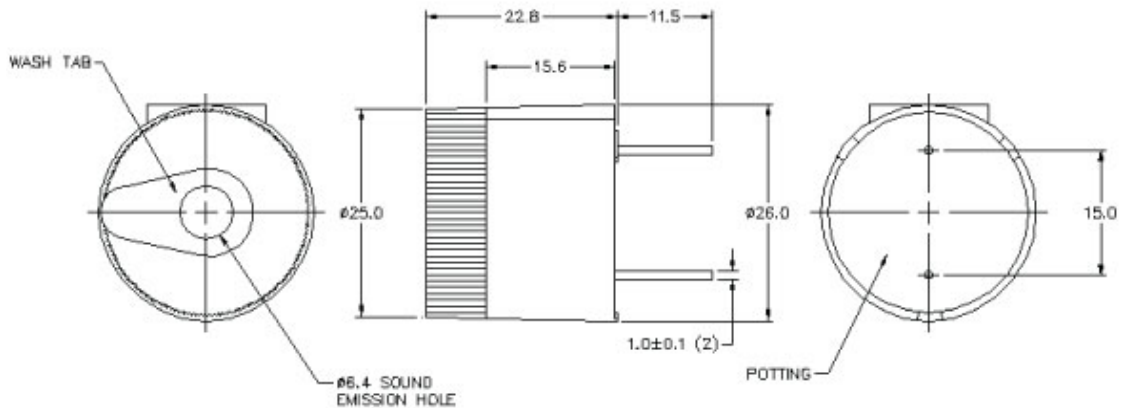

Performance

Typical SPL vs. Volts

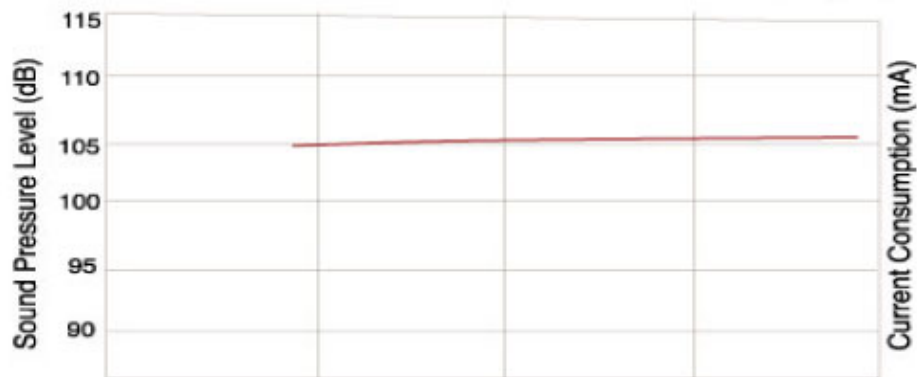

For application notes and detail drawing specifications, please consult www.projectsunlimited.com.

Specifications subject to change without notice.

© 2006, Projects Unlimited Inc., All Rights Reserved.