

Part Number: AI-4228-TWT-R



Features

Mounting: Thru Hole
Tone: Continuous
Frequency: 2800 +/- 500Hz
This part is RoHS 2002/95/EC Compliant.


Electrical Specifications

Operating Voltage	3-28 Vdc
Rated Current (Max.)	10 mA
Rated Voltage	12 Vdc
Resonant Frequency	2800 +/- 500Hz
Sound Pressure Level @ 10 cm (Min.)	99 dBA

Case: ABS
Weight: 12g
Pin Material: Au Plated Phosphor Bronze
Environmentally friendly.


Mechanical

Dimensions are in millimeters, tolerance is ± 0.5 unless otherwise specified.

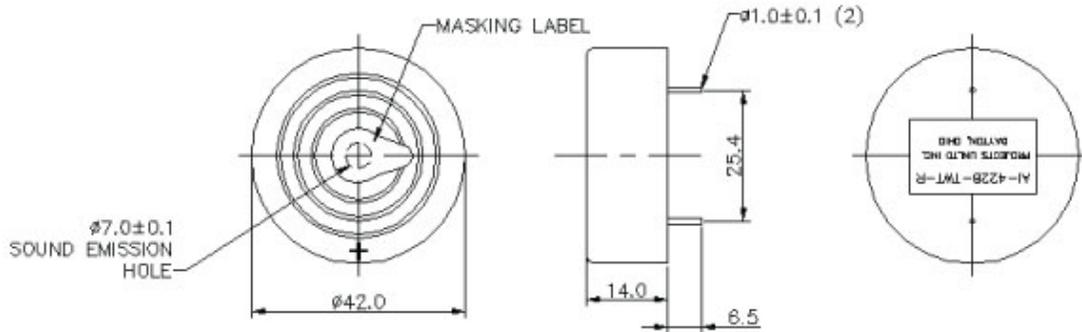

Performance

Typical SPL vs. Volts

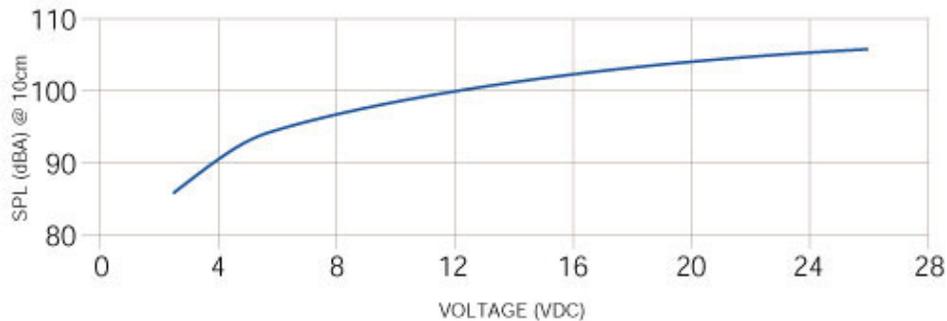

For application notes and detail drawing specifications, please consult www.projectsunlimited.com.

Specifications subject to change without notice.

© 2005, Projects Unlimited Inc., All Rights Reserved.