


Product Name // 5 Contacts 7/8" Front Panel Mounting  
Female 500mm Flying Leads

 [View Product Page](#)

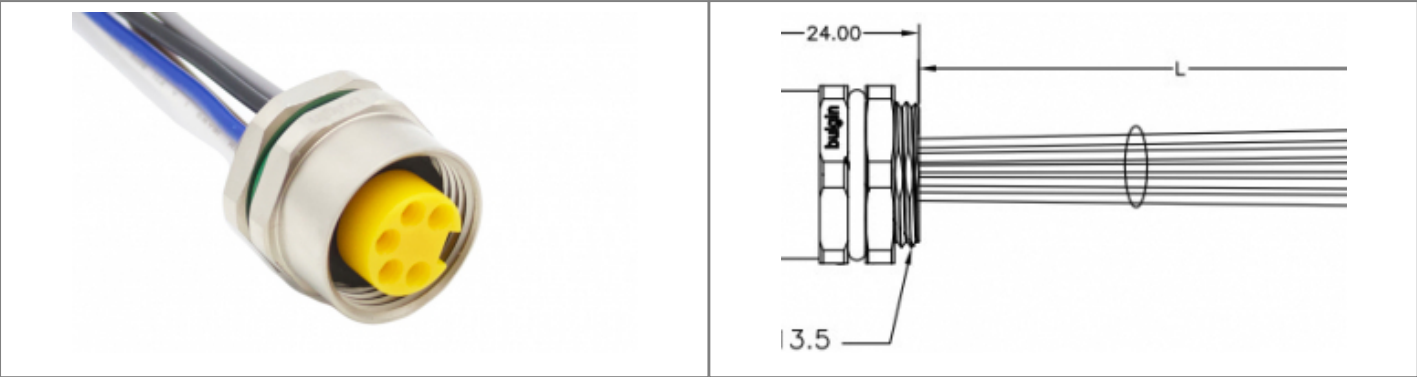

| // Product Description:                                                                                                                  |                                                                                                                          |
|------------------------------------------------------------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------------------------------------------|
|  3 Contacts 7-8" Front Panel Mounting Female 0.5M Cable |  Operating Temperature -25Â°C to +85Â°C |
|  IP67 rated when mated                                 |  Rated Voltage 300 V                   |
|  Mechanical Cycles >100                               |  ROHS compliance                      |

| // General Information:    |                                                         |
|----------------------------|---------------------------------------------------------|
| Product Display Title:     | 7/8" Front Panel Mounting Female 500mm Flying Leads     |
| Product Family:            | Circular Automation Connectors                          |
| Product Series:            | 7/8" Series                                             |
| Cable Length:              | 0.5m                                                    |
| Connection Method:         | Solder                                                  |
| Contact Type:              | Socket Contact                                          |
| Current Max:               | 9A                                                      |
| Durability:                | >100 Cycles                                             |
| Function:                  | Front Panel Mounting Female Connector with Flying Leads |
| Insulation Resistance:     | >100MOhm                                                |
| Ip Rating:                 | IP67                                                    |
| Max Operating Temperature: | +80°C                                                   |
| Min Operating Temperature: | -25°C                                                   |
| Number Of Contacts:        | 5 Contacts                                              |
| Pin Layout Code:           | A Code                                                  |
| Rohs Compliant:            | Yes                                                     |
| Thread Size:               | PG13.5                                                  |
| Voltage Max:               | 300V                                                    |

// Product PDF Links

 78 Series Circular connectors...