
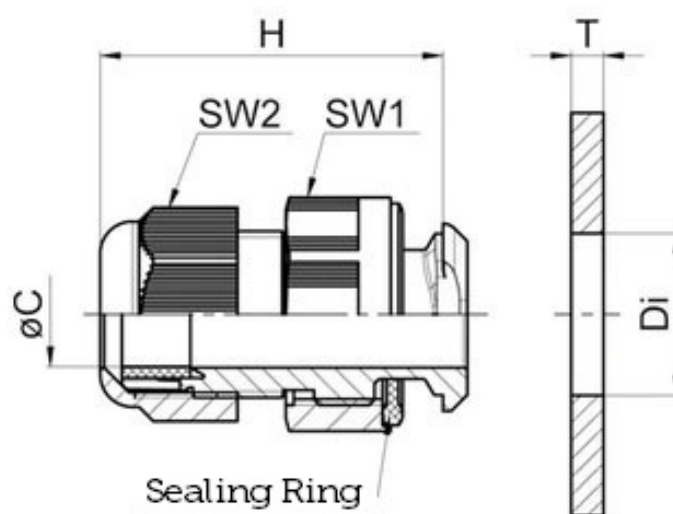


Nylon Metric Cable Glands

Range: Cable Glands/Grommets

Part Number: K341-1016-00

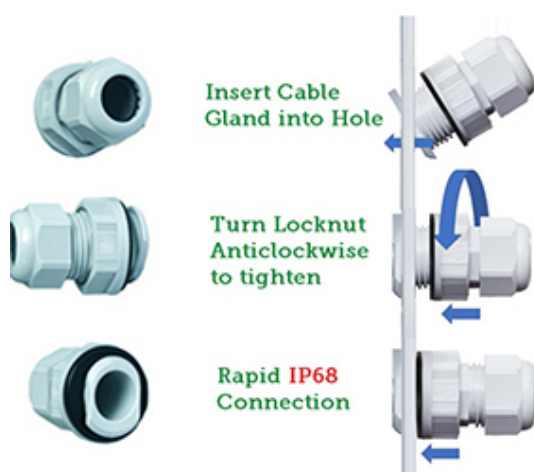

DESCRIPTION

Kwik Fix cable gland PA7035 M16

CABLE GLANDS/GROMMETS FEATURES

- IP68
- Temp range -20°C to +100°C
- Quick and easy installation without special tools
- Assemble from one side only - no separate lock nut, saves time so saves money
- Wall thickness 1-4mm

Subject to technical modification without notice.

Typographical and other errors do not justify claim for damages.

SPECIFICATION

Product Type	Standard
Sealing Ring Material	Polychloroprene-Nitrile rubber CR/NBR
Body Material	Polyamide
Mounting Nut Material	Polyamide PA6 GF30
Moulded Sealing Ring Material	Nitrile-Polytetrafluorethylene rubber NBR/PTFE
Min Temperature Rating °C	-20
Max Temperature Rating °C	100
IP Rating	68
Colour	Light Grey - RAL 7035
Hole Diameter (mm)	16.1
Thread Size	M16
Clamping Range Min (mm)	5
Clamping Range Max (mm)	10
External Connecting Thread Type	Metric
Width Across Flat 1 (mm)	24
Width Across Flat 2 (mm)	20
Height (mm)	38.5
Additional Material Detail	Body - Polyamide PA6 V-2