




Nylon Metric Cable Glands

Range: Cable Glands/Grommets

Part Number: 50007M12BS7035

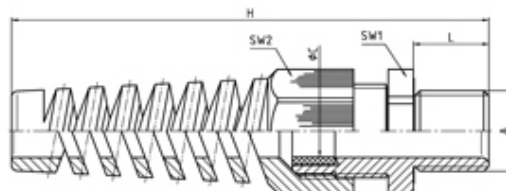

DESCRIPTION

Perfect cable gland with spiral top PA7035 M12 thread length 8, min/max cable dia 3-6.5

CABLE GLANDS/GROMMETS FEATURES

- IP68
- Temp range -20°C to +100°C
- Quick and easy installation without special tools.
- Wall thickness 1-4mm

Subject to technical modification without notice.

Typographical and other errors do not justify claim for damages.

SPECIFICATION

Product Type	Standard
Sealing Ring Material	Polychloroprene-Nitrile rubber CR/NBR
Body Material	Polyamide
Min Temperature Rating °C	-20
Max Temperature Rating °C	100
IP Rating	68
Colour	Light Grey - RAL 7035
Thread Size	M12
Clamping Range Min (mm)	3
Clamping Range Max (mm)	6.5
External Connecting Thread Type	Metric
Thread Length (mm)	8
Comments	details about tests - see annex
Width Across Flat 1 (mm)	15
Width Across Flat 2 (mm)	15
Height (mm)	63.5
Connecting Thread Size	M12x1.5
Additional Material Detail	Body - Polyamide PA6 V-2
Standards	EN50262/UL514B

INDUSTRY ACCREDITATIONS



EN