


Nylon Metric Cable Glands

Range: Cable Glands/Grommets

Part Number: K345-1025-00

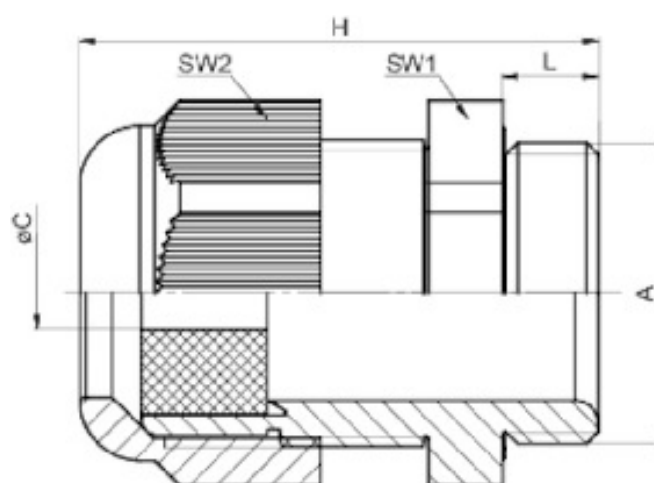

DESCRIPTION

Nylon Cable Gland, M25 x 1.5, Designed to take pre-wired cables

CABLE GLANDS/GROMMETS FEATURES

- The slotted sealing ring enables cables and leads with fixed connectors (e.g. RJ-45, USB, etc.) to be installed simply and securely
- Suitable for circular connectors with diameter up to 17mm and connectors with rectangular cross-section and diagonal up to 16,5mm
- Integrated anchorage
- Wide sealing and clamping range
- Easy -to -install

Subject to technical modification without notice.

Typographical and other errors do not justify claim for damages.

SPECIFICATION

Product Type	Nylon Cable Gland
Sealing Ring Material	NBR/SBR, slotted
Body Material	Polyamide PA6 V-2
Mounting Nut Material	Polyamide PA6 V-2
Min Temperature Rating °C	-20 °C (dynamic) -40 °C (static, short term)
Max Temperature Rating °C	+70 °C
IP Rating	IP65
Colour	Light Grey RAL7035
Hole Diameter (mm)	3-8
External Connecting Thread Type	metric, as per EN 60423
Width Across Flat 1 (mm)	29
Width Across Flat 2 (mm)	29
Height (mm)	43