




# Venting Elements/Breather Plugs

Range: Cable Glands/Grommets

Part Number: JDAE40PA/SW

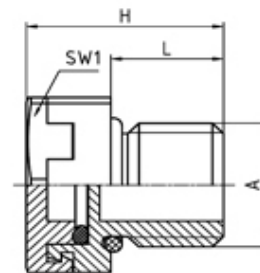

## DESCRIPTION

Venting element thread length 18 Black - RAL 9005

## CABLE GLANDS/GROMMETS FEATURES

- Typical air flow 400 ml/min/cm<sup>2</sup>; at  $\Delta p = 0,07$  bar
- Water entry pressure > 1 bar
- Temperature range -40°C/+100°C
- Protection grade IP66 / IP67 / IP69K

*Subject to technical modification without notice.*

*Typographical and other errors do not justify claim for damages.*

## SPECIFICATION

<b>Product Type</b>	Standard
<b>Body Material</b>	Polyamide
<b>Min Temperature Rating °C</b>	-40
<b>Max Temperature Rating °C</b>	100
<b>IP Rating</b>	IP66/IP67/IP69K
<b>Colour</b>	Black - RAL 9005
<b>External Connecting Thread Type</b>	Metric
<b>Thread Length (mm)</b>	18
<b>Membrane</b>	Polyether sulphone PES
<b>Typical Air Flow</b>	400 ml/min/cm <sup>2</sup> , 0,07 bar
<b>Water Entry Pressure</b>	> 1 bar
<b>Width Across Flat 1 (mm)</b>	50
<b>Height (mm)</b>	35.6
<b>Connecting Thread Size</b>	M40x1.5
<b>Test Standard</b>	Washers - Steel zinc-plated, Locknut - Brass CuZn39Pb3, nickel-plated, O-Ring - Nitrile rubber
<b>Torque Settings</b>	->2.5Nm