

Product search





Request Sample

Request Quote

87000004 RezorbTM S 200x200 mm

Part

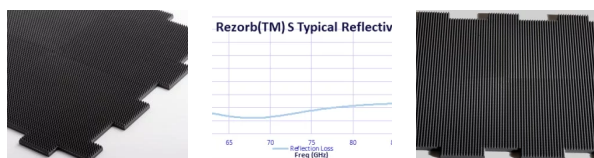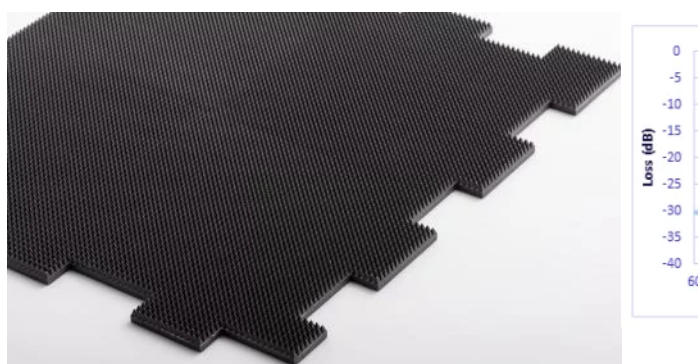

Datasheets



RFP-ABS-Rezorb (TM) S
Last updated 11/27/23

Technical Specification

Typical Properties

Color	Dark Grey
Density (g/cc)	1.55
Function	Reflectivity
Operating Temperature Max (Celsius)	177
Operating Temperature Min (Celsius)	-70
Outgassing CVCM (%)	0.220
Outgassing TML (%)	1.180
Resin	Silicone
Shelf Life	24 months from date of manufacture
Type	Reflectivity

Electromagnetic Properties

Insertion loss -10 dB

Part Frequency Range 60-90 GHz

Reflectivity -25 dB

Electrical Properties

Volume Resistivity 10 Exp7 ohm.cm

Mechanical Properties

Tensile Strength (Mpa) 1.8

Dimensions

Length (mm) 200.00

Shape Square with tab

Thickness (mm) 4.70

Width(mm) 200.00

Compliance

Lead Free Yes

REACH Yes

ROHS Compliant Yes

Static Sensitive No

UL Flammability Rating UL94 V0

Options

Option Availability - Fabric wrapping No

Option Availability - Machining No

Option Availability - PSA Yes

Option Availability - PU coating No

Option Availability - on drawing Yes

Packaging

Packaging Bulk

Cookie Preferences

[Legal](#)

[Contact](#)

[Careers](#)

[LinkedIn](#)



© Copyright 2019-2023 Laird Technologies, Inc. All rights reserved.