

# Product data sheet

Specifications

SQUARE D

Green Premium™



Safety switch, general duty, non fusible, 600A, 3 wire, 3 poles, 150hp, 240VAC, Type 1

DU326

Product availability : Stock - Normally stocked in distribution facility

## Main

Product	Single Throw Safety Switch
Duty Rating	General duty
Device Application	Residential
Disconnect Type	Non-fusible disconnect switch
Factory Installed Neutral	None
Phase	3 phase
Number of Poles	3
Current Rating	30 A
Voltage Rating	240 V AC
Enclosure Rating NEMA	NEMA 1
Motor power hp	150 hp at 240 V AC 60 Hz for 3 phase motors

## Complementary

Mounting Type	Surface
Electrical Connection	Lugs
Wiring configuration	3-wire
Wire Size	AWG 4...500 kcmil aluminium/copper
Tightening torque	450 lbf.in (50.84 N.m) (AWG 4...500 kcmil)
Depth	8.88 in (225.55 mm)
Width	24.88 in (631.95 mm)
Height	45.12 in (1146.05 mm)
Net Weight	117.07 lb(US) (53.1 kg)

## Environment

Certifications	UL listed file E2875
----------------	----------------------

## Ordering and shipping details

Category	00007-D & DU SW, NEMA1, 400-600A
Discount Schedule	DE1A

GTIN	785901461630
Returnability	Yes
Country of origin	CA

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	10.98 in (27.9 cm)
Package 1 Width	30.00 in (76.2 cm)
Package 1 Length	50.00 in (127.0 cm)
Package 1 Weight	117.00 lb(US) (53.07 kg)
Unit Type of Package 2	PAL
Number of Units in Package 2	2
Package 2 Height	35.00 in (88.9 cm)
Package 2 Width	42.00 in (106.68 cm)
Package 2 Length	60.00 in (152.4 cm)
Package 2 Weight	275.00 lb(US) (124.738 kg)


### Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information.
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
PVC free	Yes
Halogen content performance	Halogen free plastic parts product

### Contractual warranty

Warranty	18 months
----------	-----------


Dimensions

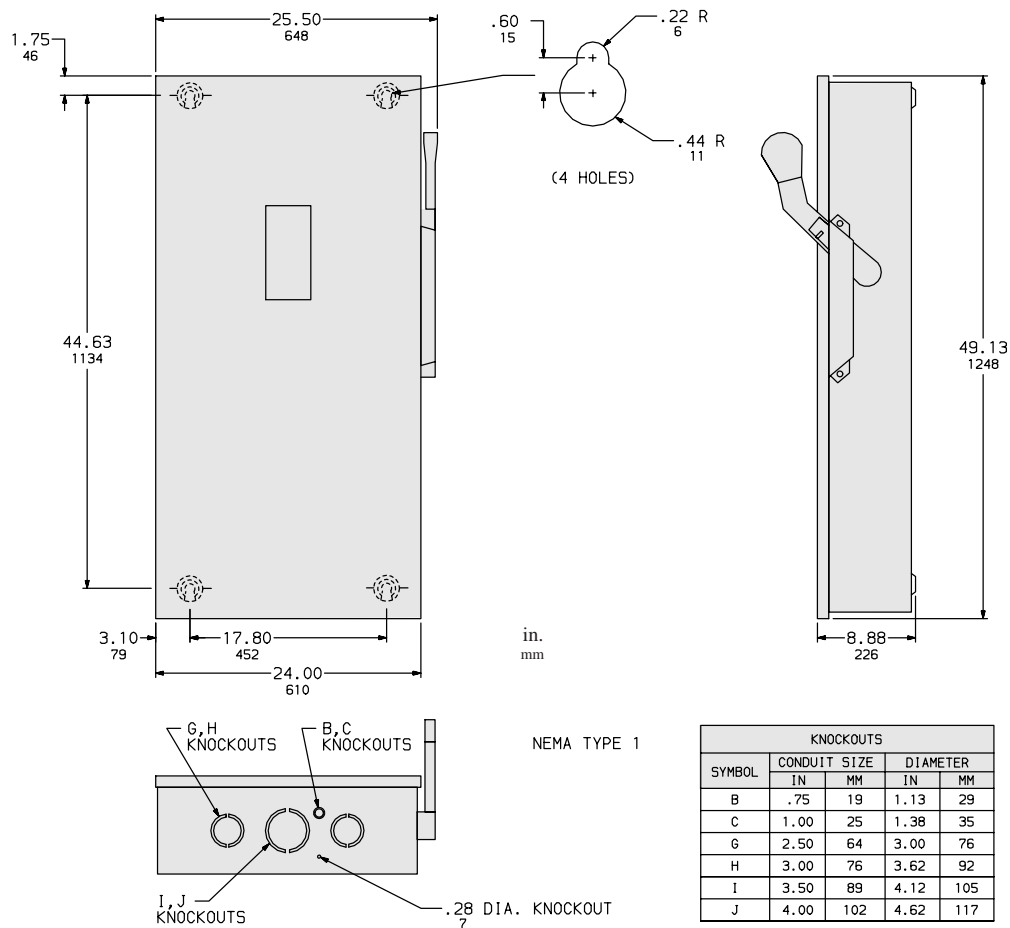

ALL DIMENSIONS ARE APPROXIMATE.  
ALSO SEE TECHNICAL DRAWINGS AND DOCUMENTATION.

Wiring Diagram

NOT FUSIBLE

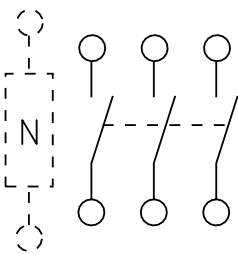

DU326

Recommended replacement(s)