


Product data sheet

Specifications

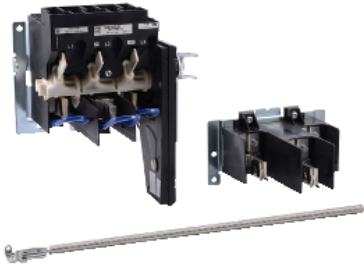

Operating mechanism, flange mounted, variable depth, 100A, 600 V, H, K, J, R fuseholder, switch mechanism

9422TEF10

Product availability : Stock - Normally stocked in distribution facility

Main

Range	9422T
Product	Disconnect Switch
Disconnect Type	Fusible disconnect switch

Complementary

Mounting Type	Flange rod variable depth
Current Rating	100 A
Horsepower Rating	25 hp 200 V AC 30 hp 230 V AC 60 hp 460 V AC 75 hp 575 V AC 20 hp 250 V DC
Fuse Rating	100 A 250/600 V
Handle Type	Ordered separately
Fuse Type	J R K H

Environment

Certifications	UL Recognized CSA
----------------	----------------------

Ordering and shipping details

Category	21732-9422
Discount Schedule	CP1
GTIN	785901879831
Returnability	No
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
------------------------	-----

Number of Units in Package 1	1
Package 1 Height	7.00 in (17.78 cm)
Package 1 Width	11.20 in (28.448 cm)
Package 1 Length	16.00 in (40.64 cm)
Package 1 Weight	6.97 lb(US) (3.162 kg)

Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Compliant EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)

Contractual warranty

Warranty	18 months
----------	-----------

Recommended replacement(s)