

# Product data sheet

Specifications

SQUARE D

Green Premium™



Enclosed molded case switch,  
QO, 60A, 2 pole, 240VAC, 22kA,  
enclosed, air conditioning

QO200TR

Product availability : Stock - Normally stocked in distribution facility

## Main

Product	Enclosed molded case switch Weatherproof enclosure
Range	QO
Current Rating	60 A
Voltage Rating	240 V AC
Color	Gray

## Complementary

Interrupt Rating	22 kA 240 V AC
Height	6.50 in (165 mm)
Width	4.65 in (118 mm)
Depth	3.90 in (99 mm)
Net Weight	3.00 lb(US) (1.361 kg)
Number of Phases	1 phase
Indoor/Outdoor Use	Enclosed outdoor
For Use With	air conditioner
Breaker compatibility	Circuit breaker QO 2P

## Environment

Certifications	UL Listed
Ambient Rating	104 °F (40 °C)
NEMA Enclosure Rating	NEMA 3R NEMA 3R outdoor

## Ordering and shipping details

Category	00044-A/C DISC & PULL-OUTS
Discount Schedule	DE2A
GTIN	785901535966
Returnability	Yes

Country of origin	MX
-------------------	----

### Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3.50 in (8.89 cm)
Package 1 Width	4.20 in (10.668 cm)
Package 1 Length	6.50 in (16.51 cm)
Package 1 Weight	3.00 lb(US) (1.361 kg)
Unit Type of Package 2	CAR
Number of Units in Package 2	10
Package 2 Height	7.10 in (18.034 cm)
Package 2 Width	9.80 in (24.892 cm)
Package 2 Length	19.80 in (50.292 cm)
Package 2 Weight	30.35 lb(US) (13.767 kg)
Unit Type of Package 3	PAL
Number of Units in Package 3	400
Package 3 Height	42.00 in (106.68 cm)
Package 3 Width	40.00 in (101.6 cm)
Package 3 Length	48.00 in (121.92 cm)
Package 3 Weight	1270.00 lb(US) (576.062 kg)


### Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
REACH free of SVHC	Yes
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS declaration</a> Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	<a href="#">Product Environmental Profile</a>


### Contractual warranty

Warranty	18 months
----------	-----------

Dimensions

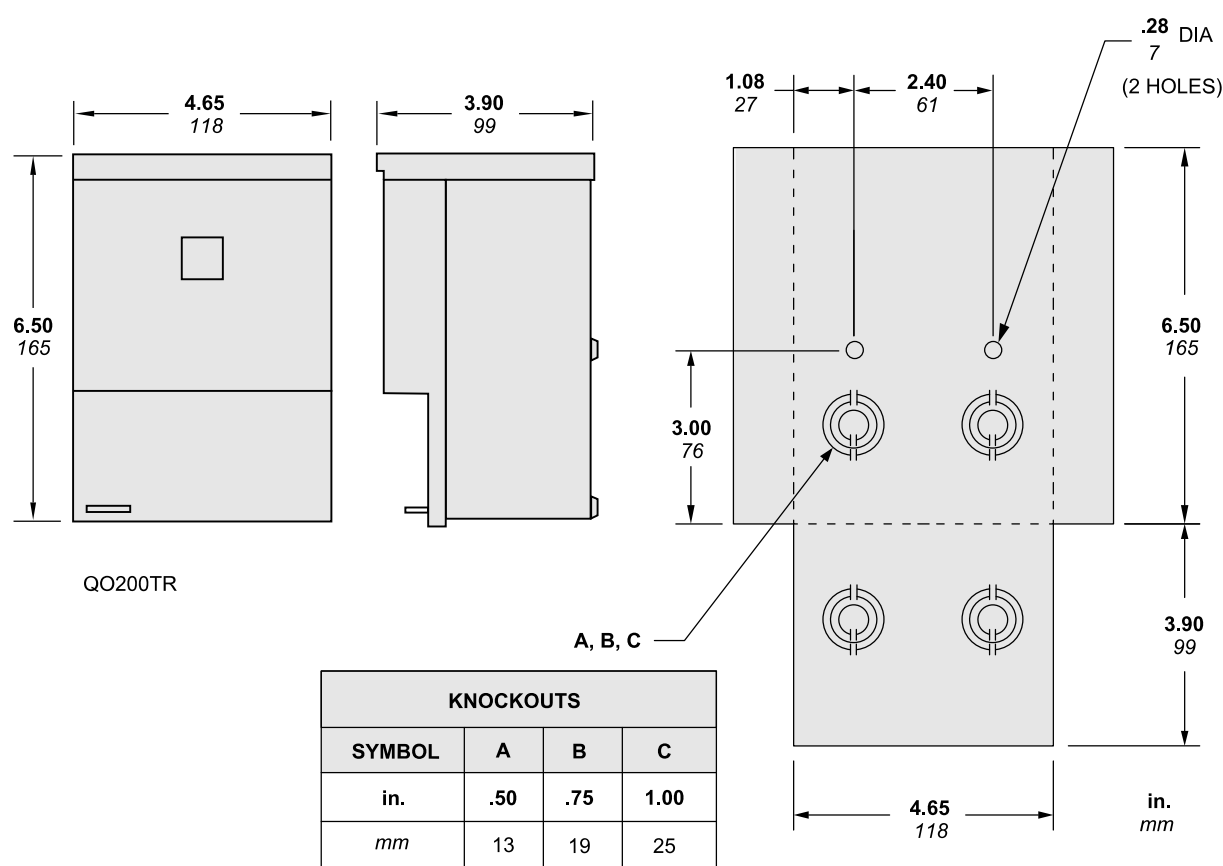

Wiring Diagram

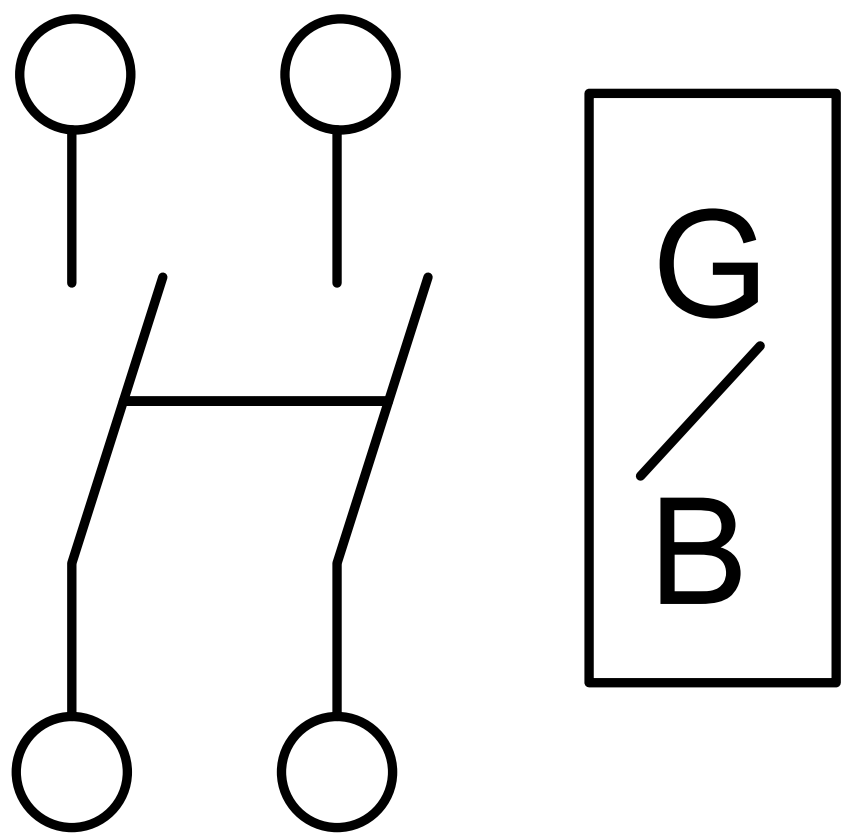

240VAC

Recommended replacement(s)