



Oblique cutters, 4231 ergo®


Oblique cutter with 20° cutting angle, for fine mechanical, telecommunication and electronics industry. Equipped with return spring. Numerically controlled machine grinding guarantees edge angle accuracy.

ISO: 5748, DIN: 5748

Finish: Black oxidised.

Material: High performance tool steel.

Cutting capacity: Copper wire

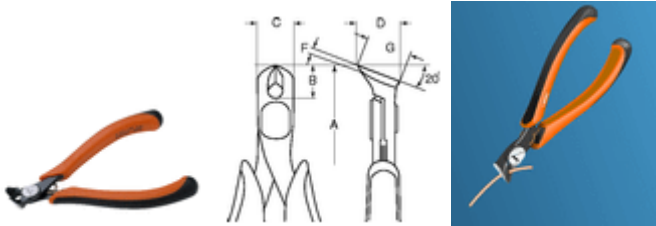

		EAN 731415+		A mm	B mm	C mm	D F G mmmmmm			
4231		0100033	3	119	9	12	10 0.5 13	0.3-1.25	Flush	55