


# ROLINE UTP Data Center Patch Cord Cat.6A (Class EA), LSOH, Slim, red, 5 m

<b>Product No.</b>	21.15.3917
<b>Manufacturer</b>	ROLINE
<b>Manufacturer No.</b>	21.15.3917
<b>EAN (single piece)</b>	7630049614970

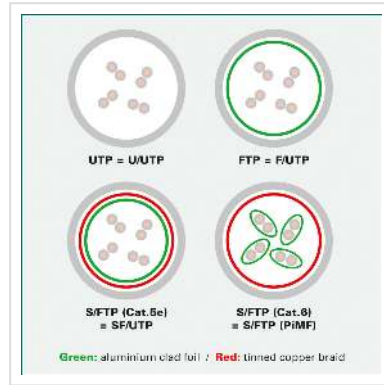

**Category 6A twisted-pair patch cable with RJ-45 connectors on both sides. Particularly thin and flexible cable with individual pairs of wires for use in confined spaces, such as in data centres.**

- Durable thanks to moulded-on kink protection
- Suitable as patch cable in patch panels or as device connection cable and intended for use in the LAN
- Contact assignment: 1:1 according to EIA/TIA568, 8 cores
- Structure: 8 cores stranded wire

## Technical specifications

Manufacturer	ROLINE
Product group	Twisted Pair Cable
Product type	UTP Patch Cables
Colour	red
Length	5 m
Shield type	UTP

Transfer quality	Cat6A / Class EA
Quantity of wires	8
Conductor type	Wire
Crossed	No
Slim cable	Yes
External cable diameter	3.4 +/- 0.2mm
Cable LSOH	Yes
Side 1 Connector Type	RJ-45
Side 1 Connector Gender	Male
Side 2 Connector Type	RJ-45
Side 2 Connector Gender	Male
Connector Type RJ45	Standard
Operating temperature min.	-10 °C
Operating temperature max.	60 °C
Weight	67.5 g
Height of packaging (single piece)	10 mm
Width of packaging (single piece)	100 mm
Depth of packaging (single piece)	100 mm
Package weight (single piece)	0.01 kg