

[Check Stock/Pricing by Product No.](#)[Search By Size and Type](#)

[Home](#) / [Products](#) / [NEMA](#) / [IP Rated Boxes](#) / [EXN Series Extruded Alumimum Enclosure](#) / Extruded Aluminum Enclosure Black EXN-23361-BK

Extruded Aluminum Enclosure Black EXN-23361-BK



5 DAY
MOD



Model # EXN-23361-BK

[EXN Series Extruded Alumimum Enclosure](#)

- Designed to allow a PCB to slide in
- Grooved exterior for faster heat removal
- Easily modified covers and body
- Enclosures include continuous gaskets and can be used indoors or outdoors (IP66)
- Anodized black
- Covers are black powder coated die-cast aluminum (ADC-12)
- The exterior design of the enclosures includes a built-in 0.02in. recessed area on which a product label can be affixed and/or printed on directly
- Specially designed exterior mounting brackets (not included)

[Compare Sizes and Models](#)[See Accessories](#)[Request Modifications](#)[Check Stock / Pricing](#)

External Size L x W x D: 1.64" x 5.77" x 6.65"

Internal Size L x W x D: 1.00" x 4.92" x 6.30"



Weight: 1.03 lbs

Color: Black

RoHS Certified: Always Compliant

IP Rating: 66

Cover Style: Opaque, Screw Down Cover, Aluminum Cover (EXN)


Gasket Type: Rubber Foam

Card Guides: Yes



Help

DRAWING

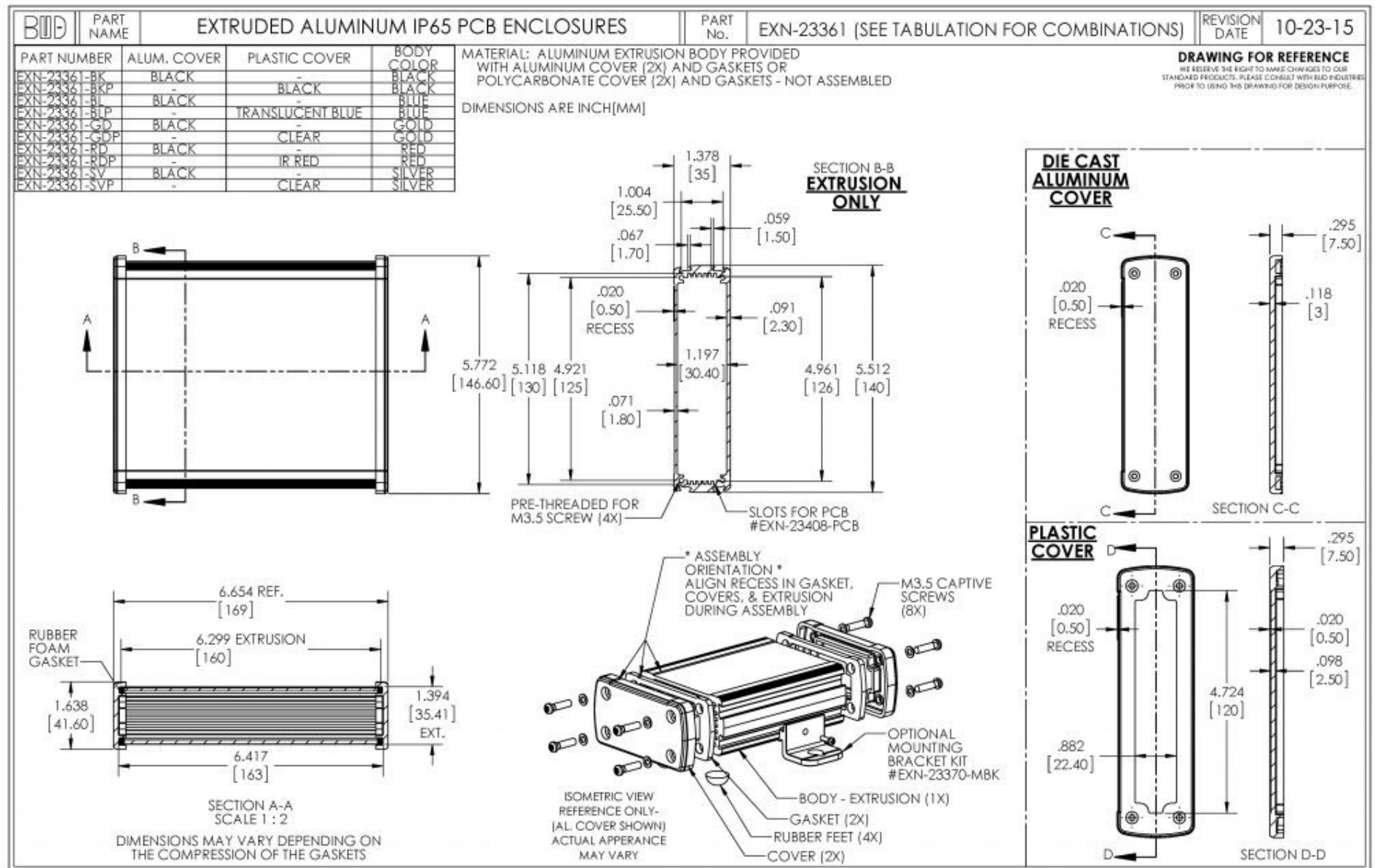

OTHER MODELS IN THIS SERIES

-- External Dimensions --

-- Internal Dimensions --

-- Cover Style --

Model #	External Dimensions	Internal Dimensions	Cover Style
EXN-23350-BK	1.39" x 2.71" x 1.93"	1.00" x 1.91" x 1.58"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23350-BKP	1.39" x 2.71" x 1.93"	1.00" x 1.91" x 1.58"	Opaque, Screw Down Cover, Plastic Cover (EXN)
EXN-23350-GD	1.39" x 2.71" x 1.93"	1.00" x 1.91" x 1.58"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23350-GDP	1.39" x 2.71" x 1.93"	1.00" x 1.91" x 1.58"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23350-BL	1.39" x 2.71" x 1.93"	1.00" x 1.91" x 1.58"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23350-BLP	1.39" x 2.71" x 1.93"	1.00" x 1.91" x 1.58"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23350-RD	1.39" x 2.71" x 1.93"	1.00" x 1.91" x 1.58"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23350-RDP	1.39" x 2.71" x 1.93"	1.00" x 1.91" x 1.58"	Infrared, Screw Down Cover, Plastic Cover (EXN)
EXN-23350-SV	1.39" x 2.71" x 1.93"	1.00" x 1.91" x 1.58"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23350-SVP	1.39" x 2.71" x 1.93"	1.00" x 1.91" x 1.58"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23351-BK	1.39" x 2.71" x 3.50"	1.00" x 1.91" x 2.99"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23351-BKP	1.39" x 2.71" x 3.50"	1.00" x 1.91" x 2.99"	Opaque, Screw Down Cover, Plastic Cover (EXN)
EXN-23351-GD	1.39" x 2.71" x 3.50"	1.00" x 1.91" x 2.99"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23351-GDP	1.39" x 2.71" x 3.50"	1.00" x 1.91" x 2.99"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23351-BL	1.39" x 2.71" x 3.50"	1.00" x 1.91" x 2.99"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23351-BLP	1.39" x 2.71" x 3.50"	1.00" x 1.91" x 2.99"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23351-RD	1.39" x 2.71" x 3.50"	1.00" x 1.91" x 2.99"	Opaque, Screw Down Cover, Aluminum Cover (EXN)





Model #	External Dimensions	Internal Dimensions ⓘ	Cover Style
EXN-23351-RDP	1.39" x 2.71" x 3.50"	1.00" x 1.91" x 2.99"	Infrared, Screw Down Cover, Plastic Cover (EXN)
EXN-23351-SV	1.39" x 2.71" x 3.50"	1.00" x 1.91" x 2.99"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23351-SVP	1.39" x 2.71" x 3.50"	1.00" x 1.91" x 2.99"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23352-BK	1.39" x 2.71" x 5.08"	1.00" x 1.91" x 4.72"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23352-BKP	1.39" x 2.71" x 5.08"	1.00" x 1.91" x 4.72"	Opaque, Screw Down Cover, Plastic Cover (EXN)
EXN-23352-GD	1.39" x 2.71" x 5.08"	1.00" x 1.91" x 4.72"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23352-GDP	1.39" x 2.71" x 5.08"	1.00" x 1.91" x 4.72"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23352-BL	1.39" x 2.71" x 5.08"	1.00" x 1.91" x 4.72"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23352-BLP	1.39" x 2.71" x 5.08"	1.00" x 1.91" x 4.72"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23352-RD	1.39" x 2.71" x 5.08"	1.00" x 1.91" x 4.72"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23352-RDP	1.39" x 2.71" x 5.08"	1.00" x 1.91" x 4.72"	Infrared, Screw Down Cover, Plastic Cover (EXN)
EXN-23352-SV	1.39" x 2.71" x 5.08"	1.00" x 1.91" x 4.72"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23352-SVP	1.39" x 2.71" x 5.08"	1.00" x 1.91" x 4.72"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23353-BK	1.39" x 4.48" x 2.72"	1.00" x 3.68" x 2.36"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23353-BKP	1.39" x 4.48" x 2.72"	1.00" x 3.68" x 2.36"	Opaque, Screw Down Cover, Plastic Cover (EXN)
EXN-23353-GD	1.39" x 4.48" x 2.72"	1.00" x 3.68" x 2.36"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23353-GDP	1.39" x 4.48" x 2.72"	1.00" x 3.68" x 2.36"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23353-BL	1.39" x 4.48" x 2.72"	1.00" x 3.68" x 2.36"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23353-BLP	1.39" x 4.48" x 2.72"	1.00" x 3.68" x 2.36"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23353-RD	1.39" x 4.48" x 2.72"	1.00" x 3.68" x 2.36"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23353-RDP	1.39" x 4.48" x 2.72"	1.00" x 3.68" x 2.36"	Infrared, Screw Down Cover, Plastic Cover (EXN)
EXN-23353-SV	1.39" x 4.48" x 2.72"	1.00" x 3.68" x 2.36"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23353-SVP	1.39" x 4.48" x 2.72"	1.00" x 3.68" x 2.36"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23354-BK	1.39" x 4.48" x 4.69"	1.00" x 3.68" x 4.33"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23354-BKP	1.39" x 4.48" x 4.69"	1.00" x 3.68" x 4.33"	Opaque, Screw Down Cover, Plastic Cover (EXN)
EXN-23354-GD	1.39" x 4.48" x 4.69"	1.00" x 3.68" x 4.33"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23354-GDP	1.39" x 4.48" x 4.69"	1.00" x 3.68" x 4.33"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23354-BL	1.39" x 4.48" x 4.69"	1.00" x 3.68" x 4.33"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23354-BLP	1.39" x 4.48" x 4.69"	1.00" x 3.68" x 4.33"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23354-RD	1.39" x 4.48" x 4.69"	1.00" x 3.68" x 4.33"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23354-RDP	1.39" x 4.48" x 4.69"	1.00" x 3.68" x 4.33"	Infrared, Screw Down Cover, Plastic Cover (EXN)
EXN-23354-SV	1.39" x 4.48" x 4.69"	1.00" x 3.68" x 4.33"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23354-SVP	1.39" x 4.48" x 4.69"	1.00" x 3.68" x 4.33"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23355-BK	1.39" x 4.48" x 6.65"	1.00" x 3.68" x 6.30"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23355-BKP	1.39" x 4.48" x 6.65"	1.00" x 3.68" x 6.30"	Opaque, Screw Down Cover, Plastic Cover (EXN)
EXN-23355-GD	1.39" x 4.48" x 6.65"	1.00" x 3.68" x 6.30"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23355-GDP	1.39" x 4.48" x 6.65"	1.00" x 3.68" x 6.30"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23355-BL	1.39" x 4.48" x 6.65"	1.00" x 3.68" x 6.30"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23355-BLP	1.39" x 4.48" x 6.65"	1.00" x 3.68" x 6.30"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23355-RD	1.39" x 4.48" x 6.65"	1.00" x 3.68" x 6.30"	Opaque, Screw Down Cover, Aluminum Cover (EXN)



Model #	External Dimensions	Internal Dimensions ⓘ	Cover Style
EXN-23355-RDP	1.39" x 4.48" x 6.65"	1.00" x 3.68" x 6.30"	Infrared, Screw Down Cover, Plastic Cover (EXN)
EXN-23355-SV	1.39" x 4.48" x 6.65"	1.00" x 3.68" x 6.30"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23355-SVP	1.39" x 4.48" x 6.65"	1.00" x 3.68" x 6.30"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23359	1.64" x 5.77" x 3.50"	1.00" x 4.92" x 3.15"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23359-BKP	1.64" x 5.77" x 3.50"	1.00" x 4.92" x 3.15"	Opaque, Screw Down Cover, Plastic Cover (EXN)
EXN-23359-GD	1.64" x 5.77" x 3.50"	1.00" x 4.92" x 3.15"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23359-GDP	1.64" x 5.77" x 3.50"	1.00" x 4.92" x 3.15"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23359-BL	1.64" x 5.77" x 3.50"	1.00" x 4.92" x 3.15"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23359-BLP	1.64" x 5.77" x 3.50"	1.00" x 4.92" x 3.15"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23359-RD	1.64" x 5.77" x 3.50"	1.00" x 4.92" x 3.15"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23359-RDP	1.64" x 5.77" x 3.50"	1.00" x 4.92" x 3.15"	Infrared, Screw Down Cover, Plastic Cover (EXN)
EXN-23359-SV	1.64" x 5.77" x 3.50"	1.00" x 4.92" x 3.15"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23359-SVP	1.64" x 5.77" x 3.50"	1.00" x 4.92" x 3.15"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23360-BK	1.64" x 5.77" x 5.08"	1.00" x 4.92" x 4.72"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23360-BKP	1.64" x 5.77" x 5.08"	1.00" x 4.92" x 4.72"	Opaque, Screw Down Cover, Plastic Cover (EXN)
EXN-23360-GD	1.64" x 5.77" x 5.08"	1.00" x 4.92" x 4.72"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23360-GDP	1.64" x 5.77" x 5.08"	1.00" x 4.92" x 4.72"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23360-BL	1.64" x 5.77" x 5.08"	1.00" x 4.92" x 4.72"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23360-BLP	1.64" x 5.77" x 5.08"	1.00" x 4.92" x 4.72"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23360-RD	1.64" x 5.77" x 5.08"	1.00" x 4.92" x 4.72"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23360-RDP	1.64" x 5.77" x 5.08"	1.00" x 4.92" x 4.72"	Infrared, Screw Down Cover, Plastic Cover (EXN)
EXN-23360-SV	1.64" x 5.77" x 5.08"	1.00" x 4.92" x 4.72"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23360-SVP	1.64" x 5.77" x 5.08"	1.00" x 4.92" x 4.72"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23361-BK	1.64" x 5.77" x 6.65"	1.00" x 4.92" x 6.30"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23361-BKP	1.64" x 5.77" x 6.65"	1.00" x 4.92" x 6.30"	Opaque, Screw Down Cover, Plastic Cover (EXN)
EXN-23361-GD	1.64" x 5.77" x 6.65"	1.00" x 4.92" x 6.30"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23361-GDP	1.64" x 5.77" x 6.65"	1.00" x 4.92" x 6.30"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23361-BL	1.64" x 5.77" x 6.65"	1.00" x 4.92" x 6.30"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23361-BLP	1.64" x 5.77" x 6.65"	1.00" x 4.92" x 6.30"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23361-RD	1.64" x 5.77" x 6.65"	1.00" x 4.92" x 6.30"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23361-RDP	1.64" x 5.77" x 6.65"	1.00" x 4.92" x 6.30"	Infrared, Screw Down Cover, Plastic Cover (EXN)
EXN-23361-SV	1.64" x 5.77" x 6.65"	1.00" x 4.92" x 6.30"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23361-SVP	1.64" x 5.77" x 6.65"	1.00" x 4.92" x 6.30"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23362-BK	1.64" x 5.77" x 8.23"	1.00" x 4.92" x 7.87"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23362-BKP	1.64" x 5.77" x 8.23"	1.00" x 4.92" x 7.87"	Opaque, Screw Down Cover, Plastic Cover (EXN)
EXN-23362-GD	1.64" x 5.77" x 8.23"	1.00" x 4.92" x 7.87"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23362-GDP	1.64" x 5.77" x 8.23"	1.00" x 4.92" x 7.87"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23362-BL	1.64" x 5.77" x 8.23"	1.00" x 4.92" x 7.87"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23362-BLP	1.64" x 5.77" x 8.23"	1.00" x 4.92" x 7.87"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23362-RD	1.64" x 5.77" x 8.23"	1.00" x 4.92" x 7.87"	Opaque, Screw Down Cover, Aluminum Cover (EXN)



Model #	External Dimensions	Internal Dimensions ⓘ	Cover Style
EXN-23362-RDP	1.64" x 5.77" x 8.23"	1.00" x 4.92" x 7.87"	Infrared, Screw Down Cover, Plastic Cover (EXN)
EXN-23362-SV	1.64" x 5.77" x 8.23"	1.00" x 4.92" x 7.87"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23362-SVP	1.64" x 5.77" x 8.23"	1.00" x 4.92" x 7.87"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23356-BK	2.03" x 4.53" x 2.72"	1.59" x 3.68" x 2.36"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23356-BKP	2.03" x 4.53" x 2.72"	1.59" x 3.68" x 2.36"	Opaque, Screw Down Cover, Plastic Cover (EXN)
EXN-23356-GD	2.03" x 4.53" x 2.72"	1.59" x 3.68" x 2.36"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23356-GDP	2.03" x 4.53" x 2.72"	1.59" x 3.68" x 2.36"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23356-BL	2.03" x 4.53" x 2.72"	1.59" x 3.68" x 2.36"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23356-BLP	2.03" x 4.53" x 2.72"	1.59" x 3.68" x 2.36"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23356-RD	2.03" x 4.53" x 2.72"	1.59" x 3.68" x 2.36"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23356-RDP	2.03" x 4.53" x 2.72"	1.59" x 3.68" x 2.36"	Infrared, Screw Down Cover, Plastic Cover (EXN)
EXN-23356-SV	2.03" x 4.53" x 2.72"	1.59" x 3.68" x 2.36"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23356-SVP	2.03" x 4.53" x 2.72"	1.59" x 3.68" x 2.36"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23357-BK	2.03" x 4.53" x 4.69"	1.59" x 3.68" x 4.33"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23357-BKP	2.03" x 4.53" x 4.69"	1.59" x 3.68" x 4.33"	Opaque, Screw Down Cover, Plastic Cover (EXN)
EXN-23357-GD	2.03" x 4.53" x 4.69"	1.59" x 3.68" x 4.33"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23357-GDP	2.03" x 4.53" x 4.69"	1.59" x 3.68" x 4.33"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23357-BL	2.03" x 4.53" x 4.69"	1.59" x 3.68" x 4.33"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23357-BLP	2.03" x 4.53" x 4.69"	1.59" x 3.68" x 4.33"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23357-RD	2.03" x 4.53" x 4.69"	1.59" x 3.68" x 4.33"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23357-RDP	2.03" x 4.53" x 4.69"	1.59" x 3.68" x 4.33"	Infrared, Screw Down Cover, Plastic Cover (EXN)
EXN-23357-SV	2.03" x 4.53" x 4.69"	1.59" x 3.68" x 4.33"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23357-SVP	2.03" x 4.53" x 4.69"	1.59" x 3.68" x 4.33"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23358-BK	2.03" x 4.53" x 6.65"	1.59" x 3.68" x 6.29"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23358-BKP	2.03" x 4.53" x 6.65"	1.59" x 3.68" x 6.29"	Opaque, Screw Down Cover, Plastic Cover (EXN)
EXN-23358-GD	2.03" x 4.53" x 6.65"	1.59" x 3.68" x 6.29"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23358-GDP	2.03" x 4.53" x 6.65"	1.59" x 3.68" x 6.29"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23358-BL	2.03" x 4.53" x 6.65"	1.59" x 3.68" x 6.29"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23358-BLP	2.03" x 4.53" x 6.65"	1.59" x 3.68" x 6.29"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23358-RD	2.03" x 4.53" x 6.65"	1.59" x 3.68" x 6.29"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23358-RDP	2.03" x 4.53" x 6.65"	1.59" x 3.68" x 6.29"	Infrared, Screw Down Cover, Plastic Cover (EXN)
EXN-23358-SV	2.03" x 4.53" x 6.65"	1.59" x 3.68" x 6.29"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23358-SVP	2.03" x 4.53" x 6.65"	1.59" x 3.68" x 6.29"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23363-BK	2.41" x 6.99" x 3.50"	2.12" x 6.10" x 3.15"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23363-BKP	2.41" x 6.99" x 3.50"	2.12" x 6.10" x 3.15"	Opaque, Screw Down Cover, Plastic Cover (EXN)
EXN-23363-GD	2.41" x 6.99" x 3.50"	2.12" x 6.10" x 3.15"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23363-GDP	2.41" x 6.99" x 3.50"	2.12" x 6.10" x 3.15"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23363-BL	2.41" x 6.99" x 3.50"	2.12" x 6.10" x 3.15"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23363-BLP	2.41" x 6.99" x 3.50"	2.12" x 6.10" x 3.15"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23363-RD	2.41" x 6.99" x 3.50"	2.12" x 6.10" x 3.15"	Opaque, Screw Down Cover, Aluminum Cover (EXN)

Model #	External Dimensions	Internal Dimensions ⓘ	Cover Style
EXN-23363-RDP	2.41" x 6.99" x 3.50"	2.12" x 6.10" x 3.15"	Infrared, Screw Down Cover, Plastic Cover (EXN)
EXN-23363-SV	2.41" x 6.99" x 3.50"	2.12" x 6.10" x 3.15"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23363-SVP	2.41" x 6.99" x 3.50"	2.12" x 6.10" x 3.15"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23364-BK	2.41" x 6.99" x 5.08"	2.12" x 6.10" x 4.92"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23364-BKP	2.41" x 6.99" x 5.08"	2.12" x 6.10" x 4.92"	Opaque, Screw Down Cover, Plastic Cover (EXN)
EXN-23364-GD	2.41" x 6.99" x 5.08"	2.12" x 6.10" x 4.92"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23364-GDP	2.41" x 6.99" x 5.08"	2.12" x 6.10" x 4.92"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23364-BL	2.41" x 6.99" x 5.08"	2.12" x 6.10" x 4.72"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23364-BLP	2.41" x 6.99" x 5.08"	2.12" x 6.10" x 4.72"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23364-RD	2.41" x 6.99" x 5.08"	2.12" x 6.10" x 4.72"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23364-RDP	2.41" x 6.99" x 5.08"	2.12" x 6.10" x 4.72"	Infrared, Screw Down Cover, Plastic Cover (EXN)
EXN-23364-SV	2.41" x 6.99" x 5.08"	2.12" x 6.10" x 4.72"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23364-SVP	2.41" x 6.99" x 5.08"	2.12" x 6.10" x 4.72"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23365-BK	2.41" x 6.99" x 6.65"	2.12" x 6.10" x 6.14"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23365-BKP	2.41" x 6.99" x 6.65"	2.12" x 6.10" x 6.14"	Opaque, Screw Down Cover, Plastic Cover (EXN)
EXN-23365-GD	2.41" x 6.99" x 6.65"	2.12" x 6.10" x 6.14"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23365-GDP	2.41" x 6.99" x 6.65"	2.12" x 6.10" x 6.14"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23365-BL	2.41" x 6.99" x 6.65"	2.12" x 6.10" x 6.30"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23365-BLP	2.41" x 6.99" x 6.65"	2.12" x 6.10" x 6.30"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23365-RD	2.41" x 6.99" x 6.65"	2.12" x 6.10" x 6.30"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23365-RDP	2.41" x 6.99" x 6.65"	2.12" x 6.10" x 6.30"	Infrared, Screw Down Cover, Plastic Cover (EXN)
EXN-23365-SV	2.41" x 6.99" x 6.65"	2.12" x 6.10" x 6.30"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23365-SVP	2.41" x 6.99" x 6.65"	2.12" x 6.10" x 6.30"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23366-BK	2.41" x 6.99" x 8.23"	2.12" x 6.10" x 7.87"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23366-BKP	2.41" x 6.99" x 8.23"	2.12" x 6.10" x 7.87"	Opaque, Screw Down Cover, Plastic Cover (EXN)
EXN-23366-GD	2.41" x 6.99" x 8.23"	2.12" x 6.10" x 7.87"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23366-GDP	2.41" x 6.99" x 8.23"	2.12" x 6.10" x 7.87"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23366-BL	2.41" x 6.99" x 8.23"	2.12" x 6.10" x 7.87"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23366-BLP	2.41" x 6.99" x 8.23"	2.12" x 6.10" x 7.87"	Clear, Screw Down Cover, Plastic Cover (EXN)
EXN-23366-RD	2.41" x 6.99" x 8.23"	2.12" x 6.10" x 7.87"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23366-RDP	2.41" x 6.99" x 8.23"	2.12" x 6.10" x 7.87"	Infrared, Screw Down Cover, Plastic Cover (EXN)
EXN-23366-SV	2.41" x 6.99" x 8.23"	2.12" x 6.10" x 7.87"	Opaque, Screw Down Cover, Aluminum Cover (EXN)
EXN-23366-SVP	2.41" x 6.99" x 8.23"	2.12" x 6.10" x 7.87"	Clear, Screw Down Cover, Plastic Cover (EXN)

ACCESSORIES






Mounting Bracket Kit EXN-23370-MBK

EXN-23370-MBK

[View Details](#)

Check Stock / Pricing

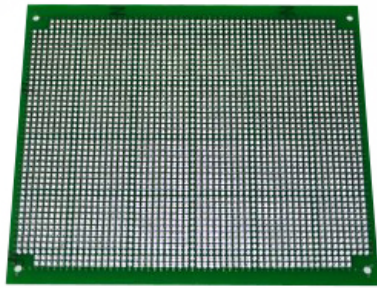

**Printed Circuit Board 5.98 x 5.11 Inches
Fits EXN-23361**

EXN-23408-PCB

[View Details](#)

Check Stock / Pricing

RELATED PRODUCT SERIES



Extruded Aluminum Box Series

VIEW SERIES DETAILS



EXT Series Extruded Aluminum Enclosures

VIEW SERIES DETAILS



[440-946-3200](tel:440-946-3200) | [Find Distributor/ Rep](#) | [Contact Us](#)



Contact Us

Name *

First

Last

Company

Email *

Phone *

State

Select One

▼

Country

Comments *

☐ I agree to receive email announcements from Bud Industries. See [Privacy Policy](#).

☐

I'm not a robot

reCAPTCHA
[Privacy](#) - [Terms](#)

Submit

