

1S51F

TRANSFORMER DRY 1PH 1KVA

600V-120/240V

Main

Product or component type	Dry Sealed Transformer
Primary Voltage	600 V
Full Capacity Taps	0
Secondary Voltage	120/240 V

Complementary

Enclosure Code	7A
Phase	1 phase
Primary to Secondary Voltage	600 V 120/240 V
Power Rating	1 kVA
Temperature rise	115 °C
Height	8.13 in (206.50 mm)
Width	6.94 in (176.28 mm)
Depth	5.31 in (134.87 mm)
Enclosure mounting	Wall mounted
Enclosure material	Painted sheet steel



Environment

Enclosure Type	NEMA 3R
Insulation temperature	356 °F (180 °C)
Product certifications	CULus UL listed CSA

Ordering and shipping details

Category	16277 - RESIN LVGP XFMR
Discount Schedule	PE2
GTIN	00785901020370
Returnability	No
Country of origin	US

Offer Sustainability


Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Phenyl glycidyl ether which is known to the State of California to cause Carcinogen & Reproductive harm. For more information go to www.p65warnings.ca.gov
RECh Regulation	 RECh Declaration
RECh free of SVHC	Yes
EU RoHS Directive	Compliant  EU RoHS Declaration
Toxic heavy metal free	Yes

Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations

Contractual warranty

Warranty	18 months
----------	-----------

Approximate Dimensions

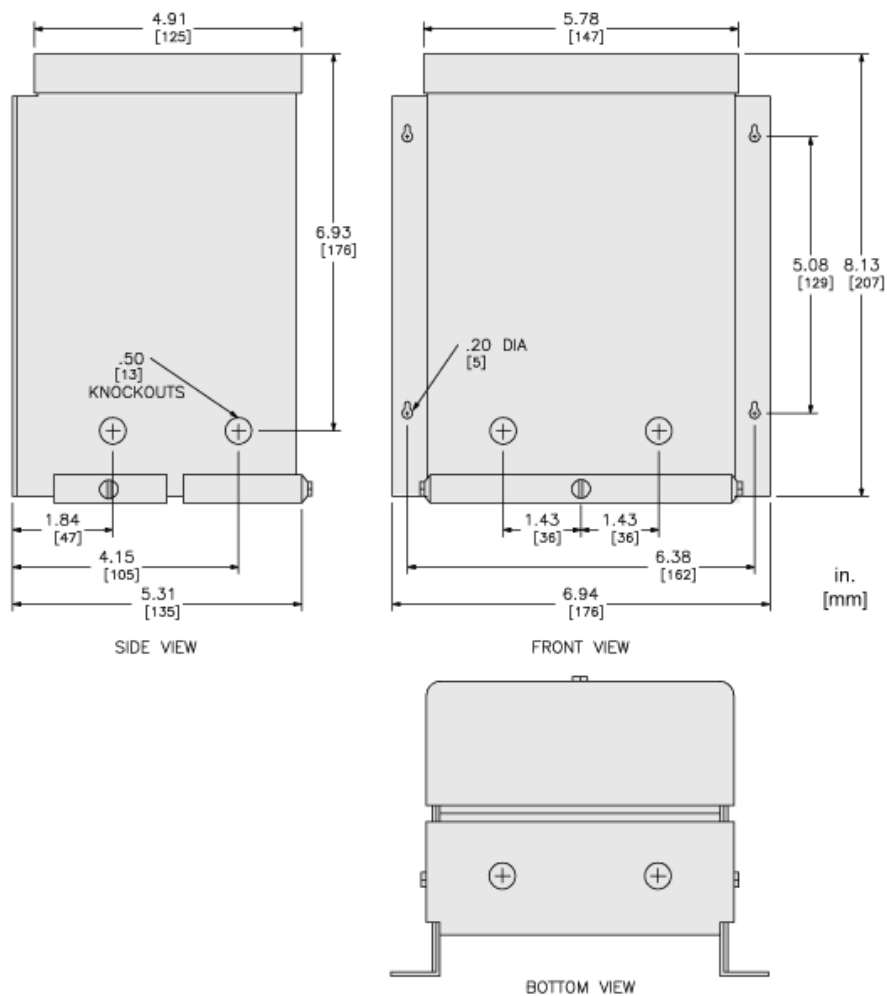

Connections and Wiring Diagrams

