


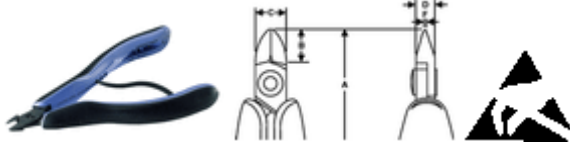







Rx Series Diagonal cutters Oval head, RX 8130-RX 8162 ergo®

These cutters are made from high performance ball bearing steel, black oxidised. Numerically controlled machine grinding guarantees edge angle accuracy and contact which increases the tools reliability and consistency. Precision induction hardened edges 63-65 HRC. Handles in two component synthetic material and come with return spring. The cutting capacity that is given is for copper wire!
 These Oval Head cutters are ideal for wire harness work and standard printed circuit board assembly.



				A mm	B mm	C mm	D F mmmm			
RX 8130		0103003	1	133.5	8.5	8.0	5 0.8 0.2-1.0	Micro	68	
RX 8131		0103010	1	133.5	8.5	8.0	5 0.8 0.1-1.0	Flush	68	
RX 8132		0103027	1	133.5	8.5	8.0	5 0.8 0.1-0.8	Ultra	68	
RX 8140		0103034	1	135.5	10.5	10.0	6 0.8 0.2-1.25	Micro	70	
RX 8141		0103041	1	135.5	10.5	10.0	6 0.8 0.1-1.25	Flush	70	
RX 8142		0103058	1	135.5	10.5	10.0	6 0.8 0.1-1.0	Ultra	70	
RX 8150		0103133	1	138.0	13.0	12.5	6 1.2 0.3-1.6	Micro	73	
RX 8151		0103140	1	138.0	13.0	12.5	6 1.2 0.2-1.6	Flush	73	
RX 8152		0103157	1	138.0	13.0	12.5	6 1.2 0.2-1.25	Ultra	73	
RX 8160		0111534	10	147.0	16.0	16.0	8 1.6 0.4-2.0	Micro	97	
RX 8161		0111541	10	147.0	16.0	16.0	8 1.6 0.3-2.0	Flush	97	
RX 8162		0111558	10	147.0	16.0	16.0	8 1.6 0.3-1.6	Ultra	97	