


6310 Series 2 X 5 Rectangular Right Angle LED Assembly

DESCRIPTION AND FEATURES

1

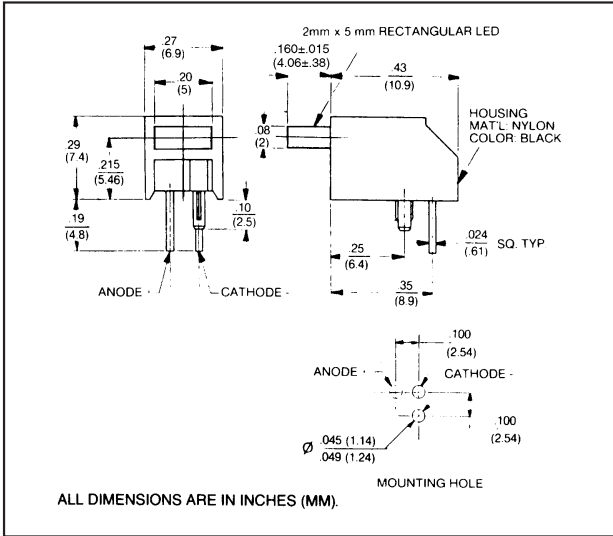

FEATURES

- Block mounting design assures height and side-by-side spacing
- Flat rectangular LED face has even light distribution
- 4 mcd typical High Brite light output-ideal for back lighting legends
- Press-in-pin secures block to board while being soldered
- Standoffs prevent flux entrapment

Housing: Black Nylon

ELECTRO-OPTICAL CHARACTERISTICS AND RATINGS

Part Number	Color	Typical Intensity (mcd)	Rated Current (mA)	Continuous Forward Current Max. (mA)	Forward Voltage Typ. (V)	Forward Voltage Max. (V)	Reverse Breakdown Voltage Min. (V)	Peak Wavelength (nm)	For More Complete LED Data (Page)
6310D1	Red	4	20	35	2.0	3.0	5	635	1-99
6310D5	Green	4	20	30	2.2	3.0	5	565	1-99
6310D7	Yellow	4	20	25	2.1	3.0	5	585	1-99