




Part Number : [1062830205](#)

Product Description : QSFP-DD MPO-to-MPO Patch Cord, 9/125µm, 3.00mm, Singlemode, 16 Fiber, 5.0m Length, Yellow Cable

Series Number : 106283

Status : Active

Product Category : Fiber Optic Cable Assemblies

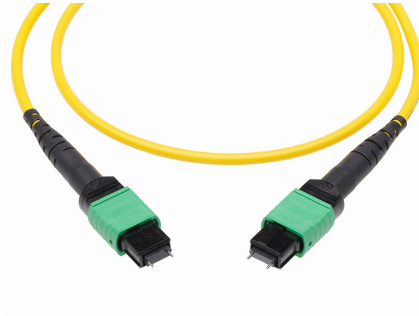

Documents & Resources

Drawings

[Drawing 1062830205_sd.pdf](#)

Specifications

[Application Specification 1062840501-000.pdf](#)

[Product Specification 1062830201-000.pdf](#)

Product Environment Compliance

Compliance

| | |
|--------------------|--------------|
| China RoHS | Not Reviewed |
| EU ELV | Not Reviewed |
| Low-Halogen Status | Not Reviewed |
| REACH SVHC | Not Reviewed |
| EU RoHS | Not Reviewed |

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

| | |
|------------------------|---|
| Status | Active |
| Category | Fiber Optic Cable Assemblies |
| Series | 106283 |
| Description | QSFP-DD MPO-to-MPO Patch Cord, 9/125µm, 3.00mm, Singlemode, 16 Fiber, 5.0m Length, Yellow Cable |
| Connector to Connector | MPO/APC-to-MPO/APC |
| Mode | Singlemode |
| Product Family | Optoelectronic Solutions |
| Product Name | MPO,QSFP-DD Optical Cables |
| UPC | 195842046382 |

Physical

| | |
|-----------------------|-------------------------------------|
| Boot Type | Straight |
| Cable Length | 5.0m |
| Cable Size | 3.00mm |
| Fiber (Core/Cladding) | 9/125µm |
| Single Ended | No |
| Wire/Cable Type | 16 Fiber SM Bend-insensitive Plenum |